


Product data sheet

Specifications

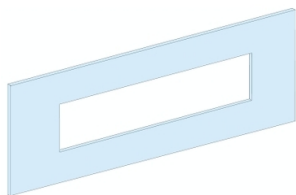

FRONT PLATE 3-4 VIGI NSX/ CVS250 VERTICAL FIXED TOGGLE WIDTH 600/650 7M

03241

⚠ Discontinued on: Apr 25, 2023

⚠ Discontinued

Main

Range	Prisma
Range Of Product	Prisma G Prisma P
Product Or Component Type	Front plate
Accessory / Separate Part Category	Installation accessory
Range Compatibility	Prisma Prisma G enclosure Prisma Prisma P cubicle
Type Of Front Plate	Cut-out
Installed Device	ComPact: fixed NSX100...160 with earth leakage protection - control: toggle - vertical installation ComPact: fixed NSX250 with earth leakage protection - control: toggle - vertical installation EasyPact: fixed CVS100...160 with earth leakage protection - control: toggle - vertical installation EasyPact: fixed CVS250 with earth leakage protection - control: toggle - vertical installation ComPact: plug-in NSX100...160 with earth leakage protection - control: toggle - vertical installation ComPact: plug-in NSX250 with earth leakage protection - control: toggle - vertical installation
Poles Description	4 x 3P: mounting plate support: CVS100...160 vertical installation 3 x 4P: mounting plate support: CVS100...160 vertical installation 4 x 3P: mounting plate support: CVS250 vertical installation 3 x 4P: mounting plate support: CVS250 vertical installation 4 x 3P: mounting plate support: NSX100...160 vertical installation 3 x 4P: mounting plate support: NSX100...160 vertical installation 4 x 3P: mounting plate support: NSX250 vertical installation 3 x 4P: mounting plate support: NSX250 vertical installation
Operating Position	Vertical

Complementary

Enclosure/Cubicle Description	Floor-standing enclosure - width 600 mm Wall-mounted enclosure - width 600 mm Cubicle - width 650 mm depth 400 mm
Connection Position	Direct connection Linery FC
Number Of Vertical Modules [50 Mm]	7
Standards	IEC 61439-1 IEC 61439-2
Product Certifications	ASEFA
Material	Steel

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Surface Finish	Matt Smooth
Protective Treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Colour	White (RAL 9001)
Height	350 mm
Width	500 mm
Net Weight	1.1 kg
Quantity Per Set	Set of 1

Functional Unit	650 mm 400 mm Prisma P cubicle EasyPact CVS100...160 with fixed toggle vertical 3P 4 direct 11
	650 mm 400 mm Prisma P cubicle EasyPact CVS100...160 with fixed toggle vertical 4P 3 direct 11
	650 mm 400 mm Prisma P cubicle EasyPact CVS250 with fixed toggle vertical 3P 4 direct 11
	650 mm 400 mm Prisma P cubicle EasyPact CVS250 with fixed toggle vertical 4P 3 direct 11
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with fixed toggle vertical 3P 4 Linergy FC 8
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with fixed toggle vertical 4P 3 Linergy FC 8
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with fixed toggle vertical 3P 4 direct 10
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with fixed toggle vertical 4P 3 direct 10
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with plug-in toggle vertical 3P 4 direct 11
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with plug-in toggle vertical 4P 3 direct 11
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with plug-in toggle vertical 3P 4 Linergy FC 9
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with plug-in toggle vertical 4P 3 Linergy FC 9
	650 mm 400 mm Prisma P cubicle ComPact NSX250 with fixed toggle vertical 3P 4 Linergy FC 9
	650 mm 400 mm Prisma P cubicle ComPact NSX250 with fixed toggle vertical 4P 3 Linergy FC 9
	650 mm 400 mm Prisma P cubicle ComPact NSX250 with fixed toggle vertical 3P 4 direct 11
	650 mm 400 mm Prisma P cubicle ComPact NSX250 with fixed toggle vertical 4P 3 direct 11
	650 mm 400 mm Prisma P cubicle ComPact NSX250 with plug-in toggle vertical 3P 4 direct 12
	650 mm 400 mm Prisma P cubicle ComPact NSX250 with plug-in toggle vertical 4P 3 direct 12
	650 mm 400 mm Prisma P cubicle ComPact NSX250 with plug-in toggle vertical 3P 4 Linergy FC 10
	650 mm 400 mm Prisma P cubicle ComPact NSX250 with plug-in toggle vertical 4P 3 Linergy FC 10
	600 mm Prisma G floor-standing enclosure EasyPact CVS100...160 with fixed toggle vertical 3P 4 direct with long terminal shield 10
	600 mm Prisma G wall-mounted enclosure EasyPact CVS100...160 with fixed toggle vertical 3P 4 direct with long terminal shield 10
	600 mm Prisma G floor-standing enclosure EasyPact CVS100...160 with fixed toggle vertical 4P 3 direct with long terminal shield 10
	600 mm Prisma G wall-mounted enclosure EasyPact CVS100...160 with fixed toggle vertical 4P 3 direct with long terminal shield 10
	600 mm Prisma G floor-standing enclosure EasyPact CVS250 with fixed toggle vertical 3P 4 direct with long terminal shield 13
	600 mm Prisma G wall-mounted enclosure EasyPact CVS250 with fixed toggle vertical 3P 4 direct with long terminal shield 13
	600 mm Prisma G floor-standing enclosure EasyPact CVS250 with fixed toggle vertical 4P 3 direct with long terminal shield 13
	600 mm Prisma G wall-mounted enclosure EasyPact CVS250 with fixed toggle vertical 4P 3 direct with long terminal shield 13
	600 mm Prisma G floor-standing enclosure ComPact NSX100...160 with fixed toggle vertical 3P 4 direct with long terminal shield 10
	600 mm Prisma G wall-mounted enclosure ComPact NSX100...160 with fixed toggle vertical 3P 4 direct with long terminal shield 10
	600 mm Prisma G floor-standing enclosure ComPact NSX100...160 with fixed toggle vertical 4P 3 direct with long terminal shield 10
	600 mm Prisma G wall-mounted enclosure ComPact NSX100...160 with fixed toggle vertical 4P 3 direct with long terminal shield 10
	600 mm Prisma G floor-standing enclosure ComPact NSX250 with fixed toggle vertical 3P 4 direct with long terminal shield 13
	600 mm Prisma G wall-mounted enclosure ComPact NSX250 with fixed toggle vertical 3P 4 direct with long terminal shield 13
	600 mm Prisma G floor-standing enclosure ComPact NSX250 with fixed toggle vertical 4P 3 direct with long terminal shield 13
	600 mm Prisma G wall-mounted enclosure ComPact NSX250 with fixed toggle vertical 4P 3 direct with long terminal shield 13

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1

Package 1 Height	2.000 cm
Package 1 Width	36.000 cm
Package 1 Length	51.000 cm
Package 1 Weight	1.140 kg
Unit Type Of Package 2	CAR
Number Of Units In Package 2	10
Package 2 Height	17.000 cm
Package 2 Width	36.500 cm
Package 2 Length	54.000 cm
Package 2 Weight	11.400 kg
Unit Type Of Package 3	P12
Number Of Units In Package 3	160
Package 3 Height	83.000 cm
Package 3 Width	80.000 cm
Package 3 Length	120.000 cm
Package 3 Weight	185.280 kg

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓ Reach Free Of Svhc

✓ Toxic Heavy Metal Free

✓ Mercury Free

✓ Rohs Exemption Information [Yes](#)

✓ Halogen Free Plastic Parts Product

Certifications & Standards

Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
-------------------	---

China Rohs Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
-----------------------	---

Environmental Disclosure	Product Environmental Profile
--------------------------	---