


# Product data sheet

Specifications

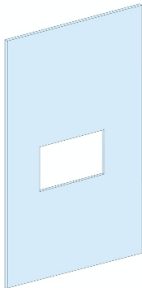

## FRONT PLATE NSX/CVS 250 VERTICAL FIXED TOGGLE/ ROTARY HANDLE W300 9M

03253

⚠ Discontinued on: Apr 25, 2023

⚠ Discontinued

### Main

Range	Prisma
Range Of Product	Prisma G
Product Or Component Type	Front plate
Accessory / Separate Part Category	Installation accessory
Range Compatibility	Prisma Prisma G duct Prisma Prisma P duct Prisma Prisma Pack 250 duct
Type Of Front Plate	Cut-out
Installed Device	ComPact: fixed NSX100...160 without earth leakage protection - control: toggle - vertical installation ComPact: fixed NSX250 without earth leakage protection - control: toggle - vertical installation EasyPact: fixed CVS100...160 without earth leakage protection - control: toggle - vertical installation EasyPact: fixed CVS100...160 without earth leakage protection - control: direct front rotary handle - vertical installation EasyPact: fixed CVS250 without earth leakage protection - control: toggle - vertical installation EasyPact: fixed CVS250 without earth leakage protection - control: direct front rotary handle - vertical installation ComPact: fixed NSX100...160 without earth leakage protection - control: direct front rotary handle - vertical installation ComPact: plug-in NSX100...160 without earth leakage protection - control: toggle - vertical installation ComPact: plug-in NSX100...160 without earth leakage protection - control: direct front rotary handle - vertical installation ComPact: plug-in NSX100...160 without earth leakage protection - control: motor mechanism - vertical installation ComPact: fixed NSX100...160 without earth leakage protection - control: motor mechanism - vertical installation ComPact: fixed NSX250 without earth leakage protection - control: direct front rotary handle - vertical installation ComPact: plug-in NSX250 without earth leakage protection - control: toggle - vertical installation ComPact: plug-in NSX250 without earth leakage protection - control: direct front rotary handle - vertical installation ComPact: plug-in NSX250 without earth leakage protection - control: motor mechanism - vertical installation ComPact: fixed NSX250 without earth leakage protection - control: motor mechanism - vertical installation
Poles Description	1 x 4P: mounting plate support: NSX100...160 vertical installation 1 x 4P: mounting plate support: NSX250 vertical installation 1 x 3P: mounting plate support: CVS100...160 vertical installation 1 x 4P: mounting plate support: CVS100...160 vertical installation 1 x 3P: mounting plate support: CVS250 vertical installation 1 x 4P: mounting plate support: CVS250 vertical installation 1 x 3P: mounting plate support: NSX100...160 vertical installation 1 x 3P: mounting plate support: NSX250 vertical installation
Operating Position	Vertical

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

# Complementary

Enclosure/Cubicle Description	Floor-standing duct - width 300 mm Wall-mounted duct - width 300 mm Cubicle duct - width 400 mm depth 400 mm Pack enclosure - width 300 mm
Connection Position	Front connection Direct connection
Number Of Vertical Modules [50 Mm]	9
Standards	IEC 61439-2 IEC 61439-1
Product Certifications	ASEFA
Material	Steel
Surface Finish	Smooth Matt
Protective Treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Colour	White (RAL 9001)
Height	450 mm
Width	300 mm
Net Weight	0.96 kg
Quantity Per Set	Set of 1

Functional Unit	300 mm Prisma G floor-standing duct ComPact NSX100...160 without fixed toggle vertical 4P 1 direct 9
	300 mm Prisma G wall-mounted duct ComPact NSX100...160 without fixed toggle vertical 4P 1 direct 9
	400 mm 400 mm Prisma P cubicle ComPact NSX100...160 without fixed toggle vertical 3P 1 front connection 9
	400 mm 400 mm Prisma P cubicle ComPact NSX100...160 without fixed toggle vertical 4P 1 front connection 9
	400 mm 400 mm Prisma P cubicle ComPact NSX100...160 without plug-in toggle vertical 3P 1 front connection 9
	400 mm 400 mm Prisma P cubicle ComPact NSX100...160 without plug-in toggle vertical 4P 1 front connection 9
	400 mm 400 mm Prisma P cubicle ComPact NSX100...160 without fixed direct front rotary handle vertical 3P 1 front connection 9
	400 mm 400 mm Prisma P cubicle ComPact NSX100...160 without fixed direct front rotary handle vertical 4P 1 front connection 9
	400 mm 400 mm Prisma P cubicle ComPact NSX100...160 without fixed motor mechanism vertical 3P 1 front connection 9
	400 mm 400 mm Prisma P cubicle ComPact NSX100...160 without fixed motor mechanism vertical 4P 1 front connection 9
	400 mm 400 mm Prisma P cubicle ComPact NSX100...160 without plug-in direct front rotary handle vertical 3P 1 front connection 9
	400 mm 400 mm Prisma P cubicle ComPact NSX100...160 without plug-in direct front rotary handle vertical 4P 1 front connection 9
	400 mm 400 mm Prisma P cubicle ComPact NSX100...160 without plug-in motor mechanism vertical 3P 1 front connection 9
	400 mm 400 mm Prisma P cubicle ComPact NSX100...160 without plug-in motor mechanism vertical 4P 1 front connection 9
	300 mm Prisma G floor-standing duct ComPact NSX250 without fixed toggle vertical 4P 1 direct 9
	300 mm Prisma G wall-mounted duct ComPact NSX250 without fixed toggle vertical 4P 1 direct 9
	400 mm 400 mm Prisma P cubicle ComPact NSX250 without fixed toggle vertical 3P 1 front connection 9
	400 mm 400 mm Prisma P cubicle ComPact NSX250 without fixed toggle vertical 4P 1 front connection 9
	400 mm 400 mm Prisma P cubicle ComPact NSX250 without plug-in toggle vertical 3P 1 front connection 9
	400 mm 400 mm Prisma P cubicle ComPact NSX250 without plug-in toggle vertical 4P 1 front connection 9
	400 mm 400 mm Prisma P cubicle ComPact NSX250 without fixed direct front rotary handle vertical 3P 1 front connection 9
	400 mm 400 mm Prisma P cubicle ComPact NSX250 without fixed direct front rotary handle vertical 4P 1 front connection 9
	400 mm 400 mm Prisma P cubicle ComPact NSX250 without fixed motor mechanism vertical 3P 1 front connection 9
	400 mm 400 mm Prisma P cubicle ComPact NSX250 without fixed motor mechanism vertical 4P 1 front connection 9
	400 mm 400 mm Prisma P cubicle ComPact NSX250 without plug-in direct front rotary handle vertical 3P 1 front connection 9
	400 mm 400 mm Prisma P cubicle ComPact NSX250 without plug-in direct front rotary handle vertical 4P 1 front connection 9
	400 mm 400 mm Prisma P cubicle ComPact NSX250 without plug-in motor mechanism vertical 3P 1 front connection 9
	400 mm 400 mm Prisma P cubicle ComPact NSX250 without plug-in motor mechanism vertical 4P 1 front connection 9
	300 mm Prisma G floor-standing duct EasyPact CVS100...160 without fixed toggle vertical 3P 1 direct with long terminal shield 9
	300 mm Prisma G wall-mounted duct EasyPact CVS100...160 without fixed toggle vertical 3P 1 direct with long terminal shield 9
	300 mm Prisma G floor-standing duct EasyPact CVS100...160 without fixed toggle vertical 4P 1 direct with long terminal shield 9
	300 mm Prisma G wall-mounted duct EasyPact CVS100...160 without fixed toggle vertical 4P 1 direct with long terminal shield 9
	300 mm Prisma G floor-standing duct EasyPact CVS250 without fixed toggle vertical 3P 1 direct with long terminal shield 9
	300 mm Prisma G wall-mounted duct EasyPact CVS250 without fixed toggle vertical 3P 1 direct with long terminal shield 9
	300 mm Prisma G floor-standing duct EasyPact CVS250 without fixed toggle vertical 4P 1 direct with long terminal shield 9
	300 mm Prisma G wall-mounted duct EasyPact CVS250 without fixed toggle vertical 4P 1 direct with long terminal shield 9
	300 mm Prisma G floor-standing duct EasyPact CVS100...160 without fixed direct front rotary handle vertical 3P 1 direct with long terminal shield 9
	300 mm Prisma G wall-mounted duct EasyPact CVS100...160 without fixed direct front rotary handle vertical 3P 1 direct with long terminal shield 9
	300 mm Prisma G floor-standing duct EasyPact CVS100...160 without fixed direct front rotary handle vertical 4P 1 direct with long terminal shield 9
	300 mm Prisma G wall-mounted duct EasyPact CVS100...160 without fixed direct front rotary handle vertical 4P 1 direct with long terminal shield 9

300 mm Prisma G floor-standing duct EasyPact CVS250 without fixed direct front rotary handle vertical 3P 1 direct with long terminal shield 9

300 mm Prisma G wall-mounted duct EasyPact CVS250 without fixed direct front rotary handle vertical 3P 1 direct with long terminal shield 9

300 mm Prisma G floor-standing duct EasyPact CVS250 without fixed direct front rotary handle vertical 4P 1 direct with long terminal shield 9

300 mm Prisma G wall-mounted duct EasyPact CVS250 without fixed direct front rotary handle vertical 4P 1 direct with long terminal shield 9

300 mm Prisma G floor-standing duct ComPact NSX100...160 without fixed toggle vertical 3P 1 direct with long terminal shield 9

300 mm Prisma G wall-mounted duct ComPact NSX100...160 without fixed toggle vertical 3P 1 direct with long terminal shield 9

300 mm Prisma G floor-standing duct ComPact NSX100...160 without fixed toggle vertical 4P 1 direct with long terminal shield 9

300 mm Prisma G wall-mounted duct ComPact NSX100...160 without fixed toggle vertical 4P 1 direct with long terminal shield 9

300 mm Prisma G floor-standing duct ComPact NSX100...160 without fixed direct front rotary handle vertical 3P 1 direct with long terminal shield 9

300 mm Prisma G wall-mounted duct ComPact NSX100...160 without fixed direct front rotary handle vertical 3P 1 direct with long terminal shield 9

300 mm Prisma G floor-standing duct ComPact NSX100...160 without fixed direct front rotary handle vertical 4P 1 direct with long terminal shield 9

300 mm Prisma G wall-mounted duct ComPact NSX100...160 without fixed direct front rotary handle vertical 4P 1 direct with long terminal shield 9

300 mm Prisma Pack 250 Pack enclosure ComPact NSX100...160 without fixed toggle vertical 3P 1 direct with long terminal shield 9

300 mm Prisma Pack 250 Pack enclosure ComPact NSX100...160 without fixed toggle vertical 4P 1 direct with long terminal shield 9

300 mm Prisma G floor-standing duct ComPact NSX250 without fixed toggle vertical 3P 1 direct with long terminal shield 9

300 mm Prisma G wall-mounted duct ComPact NSX250 without fixed toggle vertical 3P 1 direct with long terminal shield 9

300 mm Prisma G floor-standing duct ComPact NSX250 without fixed toggle vertical 4P 1 direct with long terminal shield 9

300 mm Prisma G wall-mounted duct ComPact NSX250 without fixed toggle vertical 4P 1 direct with long terminal shield 9

300 mm Prisma G floor-standing duct ComPact NSX250 without fixed direct front rotary handle vertical 3P 1 direct with long terminal shield 9

300 mm Prisma G wall-mounted duct ComPact NSX250 without fixed direct front rotary handle vertical 3P 1 direct with long terminal shield 9

300 mm Prisma G floor-standing duct ComPact NSX250 without fixed direct front rotary handle vertical 4P 1 direct with long terminal shield 9

300 mm Prisma G wall-mounted duct ComPact NSX250 without fixed direct front rotary handle vertical 4P 1 direct with long terminal shield 9

300 mm Prisma Pack 250 Pack enclosure ComPact NSX250 without fixed toggle vertical 3P 1 direct with long terminal shield 9

300 mm Prisma Pack 250 Pack enclosure ComPact NSX250 without fixed toggle vertical 4P 1 direct with long terminal shield 9

# Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	5.000 cm
Package 1 Width	26.000 cm
Package 1 Length	46.000 cm
Package 1 Weight	940.000 g
Unit Type Of Package 2	CAR
Number Of Units In Package 2	10
Package 2 Height	17.000 cm
Package 2 Width	27.500 cm
Package 2 Length	52.500 cm
Package 2 Weight	9.900 kg
Unit Type Of Package 3	P12
Number Of Units In Package 3	60
Package 3 Height	35.000 cm
Package 3 Width	80.000 cm
Package 3 Length	120.000 cm
Package 3 Weight	59.520 kg

## Sustainability

**Green Premium™ label** is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency   RoHS/REACH

## Well-being performance

✓ Reach Free Of Svhc

✓ Toxic Heavy Metal Free

✓ Mercury Free

✓ Rohs Exemption Information   [Yes](#)

✓ Halogen Free Plastic Parts Product

## Certifications & Standards

<b>Eu Rohs Directive</b>	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
--------------------------	---

<b>China Rohs Regulation</b>	<a href="#">China RoHS declaration</a> Pro-active China RoHS declaration (out of China RoHS legal scope)
------------------------------	---

<b>Environmental Disclosure</b>	<a href="#">Product Environmental Profile</a>
---------------------------------	---