


Product data sheet

Specifications

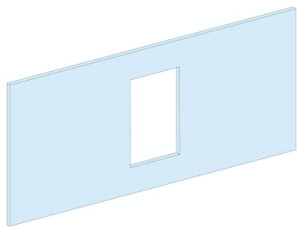

FRONT PLATE INS630 HORIZONTAL W600 9M

03271

⚠ Discontinued on: Apr 25, 2023

⚠ Discontinued

Main

Range	Prisma
Range Of Product	Prisma G
Product Or Component Type	Front plate
Accessory / Separate Part Category	Installation accessory
Range Compatibility	Prisma Prisma G enclosure
Type Of Front Plate	Cut-out
Installed Device	ComPact: fixed INS320...400 - control: direct front rotary handle - horizontal installation ComPact: fixed INS500...630 - control: direct front rotary handle - horizontal installation ComPact: fixed INV320...400 - control: direct front rotary handle - horizontal installation ComPact: fixed INV500...630 - control: direct front rotary handle - horizontal installation
Poles Description	1 x 3P: mounting plate support: INS320...400 horizontal installation 1 x 4P: mounting plate support: INS320...400 horizontal installation 1 x 3P: mounting plate support: INS500...630 horizontal installation 1 x 4P: mounting plate support: INS500...630 horizontal installation 1 x 3P: mounting plate support: INV320...400 horizontal installation 1 x 4P: mounting plate support: INV320...400 horizontal installation 1 x 3P: mounting plate support: INV500...630 horizontal installation 1 x 4P: mounting plate support: INV500...630 horizontal installation
Operating Position	Horizontal

Complementary

Enclosure/Cubicle Description	Floor-standing enclosure + duct - width 600 + 300 mm Wall-mounted enclosure + duct - width 600 + 300 mm
Connection Position	Direct connection
Number Of Vertical Modules [50 Mm]	6
Standards	IEC 61439-1 IEC 61439-2
Product Certifications	ASEFA
Material	Steel
Surface Finish	Smooth Matt
Protective Treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Colour	White (RAL 9001)
Height	300 mm

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Package 1 Width	31.000 cm
Package 1 Length	51.000 cm
Package 1 Weight	1.080 kg
Unit Type Of Package 2	CAR
Number Of Units In Package 2	10
Package 2 Height	17.000 cm
Package 2 Width	32.000 cm
Package 2 Length	53.000 cm
Package 2 Weight	11.220 kg
Unit Type Of Package 3	P12
Number Of Units In Package 3	90
Package 3 Height	48.000 cm
Package 3 Width	80.000 cm
Package 3 Length	120.000 cm
Package 3 Weight	100.980 kg

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓ Reach Free Of Svhc

✓ Toxic Heavy Metal Free

✓ Mercury Free

✓ Rohs Exemption Information [Yes](#)

✓ Halogen Free Plastic Parts Product

Certifications & Standards

Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
--------------------------	---

China Rohs Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
------------------------------	---

Environmental Disclosure	Product Environmental Profile
---------------------------------	---