



# Product data sheet

Specifications

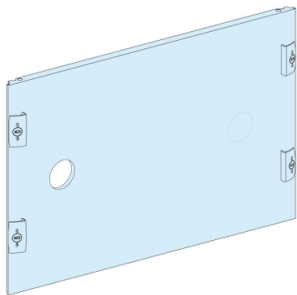

## FRONT PLATE INF63 V.4P-INF160 V.3/4P WIDTH 600/650 5M

03315

 **Discontinued on:** Dec 31, 2020

 **Discontinued**

### Main

Range	Prisma
Range Of Product	Prisma G Prisma P
Product Or Component Type	Front plate
Accessory / Separate Part Category	Installation accessory
Range Compatibility	Prisma Prisma G enclosure Prisma Prisma P cubicle
Type Of Front Plate	Cut-out
Installed Device	FuPact: fixed INF63 - control: extended rotary handle - vertical installation FuPact: fixed INF100...160 - control: extended rotary handle - vertical installation
Poles Description	2 x 3P: mounting plate support: INF100...160 vertical installation 2 x 4P: mounting plate support: INF100...160 vertical installation 2 x 4P: mounting plate support: INF63 vertical installation
Operating Position	Vertical

### Complementary

Enclosure/Cubicle Description	Floor-standing enclosure - width 600 mm Wall-mounted enclosure - width 600 mm Cubicle - width 650 mm depth 400 mm
Connection Position	Direct connection
Number Of Vertical Modules [50 Mm]	5
Standards	IEC 61439-1 IEC 61439-2
Product Certifications	ASEFA
Material	Steel
Surface Finish	Smooth Matt
Protective Treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Colour	White (RAL 9001)
Height	250 mm
Width	500 mm
Net Weight	1.04 kg
Quantity Per Set	Set of 1

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Functional Unit	600 mm Prisma G floor-standing enclosure FuPact INF100...160 fixed extended rotary handle vertical 3P 2 direct 7 600 mm Prisma G wall-mounted enclosure FuPact INF100...160 fixed extended rotary handle vertical 3P 2 direct 7 600 mm Prisma G floor-standing enclosure FuPact INF100...160 fixed extended rotary handle vertical 4P 2 direct 7 600 mm Prisma G wall-mounted enclosure FuPact INF100...160 fixed extended rotary handle vertical 4P 2 direct 7 650 mm 400 mm Prisma P cubicle FuPact INF100...160 fixed extended rotary handle vertical 3P 2 direct 5 650 mm 400 mm Prisma P cubicle FuPact INF100...160 fixed extended rotary handle vertical 4P 2 direct 5 600 mm Prisma G floor-standing enclosure FuPact INF63 fixed extended rotary handle vertical 4P 2 direct 5 600 mm Prisma G wall-mounted enclosure FuPact INF63 fixed extended rotary handle vertical 4P 2 direct 5 650 mm 400 mm Prisma P cubicle FuPact INF63 fixed extended rotary handle vertical 4P 2 direct 5
-----------------	---

## Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	3 cm
Package 1 Width	26 cm
Package 1 Length	51 cm
Package 1 Weight	1.05 kg

## Sustainability

**Green Premium™ label** is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency   RoHS/REACH

## Well-being performance

✓ Reach Free Of Svhc

✓ Toxic Heavy Metal Free

✓ Mercury Free

✓ Rohs Exemption Information   Yes

✓ Halogen Free Plastic Parts Product

## Certifications & Standards

Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
-------------------	---

China Rohs Regulation	<a href="#">China RoHS declaration</a> Pro-active China RoHS declaration (out of China RoHS legal scope)
-----------------------	---

Environmental Disclosure	<a href="#">Product Environmental Profile</a>
--------------------------	---