


Product data sheet

Specifications

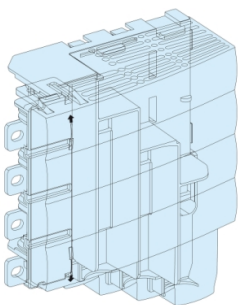

INCOMER CONNECTION BLOCK NSX/INS/INV250 4P BOTTOM

04067

 **Discontinued on:** Apr 25, 2023

 **Discontinued**

Main

Range	Prisma
Range Of Product	Prisma G
Product Or Component Type	Incoming connection block
Product Name	Prisma Prisma G enclosure
Accessory / Separate Part Category	Connection accessory
Standards	IEC 61439-2 IEC 61439-1
Product Certifications	ASEFA

Complementary

Location Of Connection	Bottom
Installation Description	Floor-standing enclosure - width 600 mm Wall-mounted enclosure - width 600 mm Floor-standing enclosure - width 850 mm Floor-standing enclosure + duct - width 600 + 300 mm Wall-mounted enclosure + duct - width 600 + 300 mm
Installed Device	ComPact: fixed INS250 - control: direct front rotary handle horizontal installation ComPact: fixed INV250 - control: direct front rotary handle horizontal installation ComPact: fixed INV100 - control: direct front rotary handle horizontal installation ComPact: fixed NSX100...160 without earth leakage protection - control: toggle horizontal installation ComPact: fixed NSX250 without earth leakage protection - control: toggle horizontal installation ComPact: fixed INV160 - control: direct front rotary handle horizontal installation ComPact: fixed INV200 - control: direct front rotary handle horizontal installation
[Ie] Rated Operational Current	250 A
[In] Rated Current	250 A
Net Weight	1.48 kg
Quantity Per Set	Set of 1

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

850 mm Prisma G floor-standing enclosure ComPact INV200 fixed direct front rotary handle horizontal 3P 1 connection block 5

850 mm Prisma G floor-standing enclosure ComPact INV200 fixed direct front rotary handle horizontal 4P 1 connection block 5

600 + 300 mm Prisma G floor-standing enclosure + duct ComPact INS250 fixed direct front rotary handle horizontal 4P 1 connection block 5

600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact INS250 fixed direct front rotary handle horizontal 4P 1 connection block 5

600 + 300 mm Prisma G floor-standing enclosure + duct ComPact INV100 fixed direct front rotary handle horizontal 4P 1 connection block 5

600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact INV100 fixed direct front rotary handle horizontal 4P 1 connection block 5

600 + 300 mm Prisma G floor-standing enclosure + duct ComPact INV160 fixed direct front rotary handle horizontal 4P 1 connection block 5

600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact INV160 fixed direct front rotary handle horizontal 4P 1 connection block 5

600 + 300 mm Prisma G floor-standing enclosure + duct ComPact INV200 fixed direct front rotary handle horizontal 4P 1 connection block 5

600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact INV200 fixed direct front rotary handle horizontal 4P 1 connection block 5

600 + 300 mm Prisma G floor-standing enclosure + duct ComPact INV250 fixed direct front rotary handle horizontal 4P 1 connection block 5

600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact INV250 fixed direct front rotary handle horizontal 4P 1 connection block 5

600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX100...160 without fixed toggle horizontal 4P 1 connection block 5

600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX100...160 without fixed toggle horizontal 4P 1 connection block 5

600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX250 without fixed toggle horizontal 4P 1 connection block 5

600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX250 without fixed toggle horizontal 4P 1 connection block 5

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	11.5 cm
Package 1 Width	21.5 cm
Package 1 Length	23.5 cm
Package 1 Weight	1.49 kg
Unit Type Of Package 2	P12
Number Of Units In Package 2	90
Package 2 Height	84.0 cm
Package 2 Width	80.0 cm
Package 2 Length	120.0 cm
Package 2 Weight	146.0 kg

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓ Reach Free Of Svhc

✓ Toxic Heavy Metal Free

✓ Mercury Free

✓ Rohs Exemption Information [Yes](#)

Certifications & Standards

Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
-------------------	---

China Rohs Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
-----------------------	---

Environmental Disclosure	Product Environmental Profile
--------------------------	---