


Product data sheet

Specifications

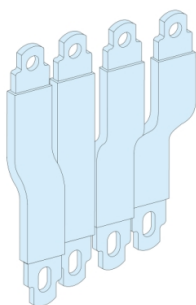

CU CONNECTION NSX/CVS/INS 630 V.4P/ STAGED BUSBAR LINERGY BS

04075

⚠ Discontinued on: Dec 15, 2021

⚠ Discontinued

Main

Range	Prisma
Range Of Product	Prisma G
Product Or Component Type	Connection
Product Name	Prisma Prisma G duct
Accessory / Separate Part Category	Current distribution accessory
Standards	IEC 61439-2 IEC 61439-1
Product Certifications	ASEFA

Complementary

Cubicle-Device Connection	Linery BS busbar
Installation Description	Floor-standing duct - width 300 mm Wall-mounted duct - width 300 mm
Installed Device	ComPact: fixed NSX400 without earth leakage protection - control: toggle vertical installation ComPact: fixed NSX400 without earth leakage protection - control: direct front rotary handle vertical installation ComPact: fixed NSX400 with earth leakage protection - control: toggle vertical installation EasyPact: fixed CVS400 without earth leakage protection - control: toggle vertical installation EasyPact: fixed CVS630 without earth leakage protection - control: toggle vertical installation EasyPact: fixed CVS400 without earth leakage protection - control: direct front rotary handle vertical installation EasyPact: fixed CVS630 without earth leakage protection - control: direct front rotary handle vertical installation EasyPact: fixed CVS400 with earth leakage protection - control: toggle vertical installation EasyPact: fixed CVS630 with earth leakage protection - control: toggle vertical installation ComPact: fixed NSX630 without earth leakage protection - control: toggle vertical installation ComPact: fixed NSX630 without earth leakage protection - control: direct front rotary handle vertical installation ComPact: fixed NSX630 with earth leakage protection - control: toggle vertical installation ComPact: fixed INS320...400 - control: direct front rotary handle vertical installation ComPact: fixed INS500...630 - control: direct front rotary handle vertical installation ComPact: fixed INV320...400 - control: direct front rotary handle vertical installation ComPact: fixed INV500...630 - control: direct front rotary handle vertical installation
[Ie] Rated Operational Current	630 A
[In] Rated Current	630 A
Net Weight	2.28 kg

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

300 mm Prisma G floor-standing duct ComPact NSX630 without fixed toggle vertical
3P 1 direct with long terminal shield 12

300 mm Prisma G wall-mounted duct ComPact NSX630 without fixed toggle vertical
3P 1 direct with long terminal shield 12

300 mm Prisma G floor-standing duct ComPact NSX630 without fixed toggle vertical
4P 1 direct with long terminal shield 12

300 mm Prisma G wall-mounted duct ComPact NSX630 without fixed toggle vertical
4P 1 direct with long terminal shield 12

300 mm Prisma G floor-standing duct ComPact NSX630 without fixed direct front
rotary handle vertical 3P 1 direct with long terminal shield 12

300 mm Prisma G wall-mounted duct ComPact NSX630 without fixed direct front
rotary handle vertical 3P 1 direct with long terminal shield 12

300 mm Prisma G floor-standing duct ComPact NSX630 without fixed direct front
rotary handle vertical 4P 1 direct with long terminal shield 12

300 mm Prisma G wall-mounted duct ComPact NSX630 without fixed direct front
rotary handle vertical 4P 1 direct with long terminal shield 12

300 mm Prisma G floor-standing duct EasyPact CVS400 with fixed toggle vertical 3P
1 direct with long terminal shield 13

300 mm Prisma G wall-mounted duct EasyPact CVS400 with fixed toggle vertical 3P
1 direct with long terminal shield 13

300 mm Prisma G floor-standing duct EasyPact CVS400 with fixed toggle vertical 4P
1 direct with long terminal shield 13

300 mm Prisma G wall-mounted duct EasyPact CVS400 with fixed toggle vertical 4P
1 direct with long terminal shield 13

300 mm Prisma G floor-standing duct EasyPact CVS630 with fixed toggle vertical 3P
1 direct with long terminal shield 13

300 mm Prisma G wall-mounted duct EasyPact CVS630 with fixed toggle vertical 3P
1 direct with long terminal shield 13

300 mm Prisma G floor-standing duct EasyPact CVS630 with fixed toggle vertical 4P
1 direct with long terminal shield 13

300 mm Prisma G wall-mounted duct EasyPact CVS630 with fixed toggle vertical 4P
1 direct with long terminal shield 13

300 mm Prisma G floor-standing duct ComPact NSX400 with fixed toggle vertical 3P
1 direct with long terminal shield 14

300 mm Prisma G wall-mounted duct ComPact NSX400 with fixed toggle vertical 3P
1 direct with long terminal shield 14

300 mm Prisma G floor-standing duct ComPact NSX400 with fixed toggle vertical 4P
1 direct with long terminal shield 14

300 mm Prisma G wall-mounted duct ComPact NSX400 with fixed toggle vertical 4P
1 direct with long terminal shield 14

300 mm Prisma G floor-standing duct ComPact NSX630 with fixed toggle vertical 3P
1 direct with long terminal shield 14

300 mm Prisma G wall-mounted duct ComPact NSX630 with fixed toggle vertical 3P
1 direct with long terminal shield 14

300 mm Prisma G floor-standing duct ComPact NSX630 with fixed toggle vertical 4P
1 direct with long terminal shield 14

300 mm Prisma G wall-mounted duct ComPact NSX630 with fixed toggle vertical 4P
1 direct with long terminal shield 14

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓	Reach Free Of Svhc	
✓	Toxic Heavy Metal Free	
✓	Mercury Free	
✓	Rohs Exemption Information	Yes

Certifications & Standards

Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
China Rohs Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile