

Main

Range	Prisma
Product name	Prisma G
IP degree of protection	IP40 with door IP30 without door IP41 with door and canopy IP43 with door, canopy and IP43 gasket
Product or component type	Door
Type of door	Transparent
Provided equipment	Door Handle Keylock (key 405) Other keylock and insert (to be ordered separately) Hinge (x3)

Complementary

Door opening side	Reversible
Number of locks	3
Door opening angle	130 °
Installation description	Floor-standing enclosure - width 600 mm Extension enclosure - width 600 mm
Number of vertical modules [50 mm]	33
Enclosure material	Handle : polyamide Cover frame : treated sheet steel Glass
Quantity per set	Set of 1
Height	1830 mm
Width	600 mm
Depth	33 mm
Product weight	11.54 kg
Material	Glass
Surface finish	Matt Smooth

Colour	White RAL 9001
--------	----------------

Environment

IK degree of protection	IK08 conforming to EN/IEC 62262
Standards	IEC 61439-2 IEC 61439-1
Protective treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder


Offer Sustainability

Sustainable offer status	Green Premium product
RoHS (date code: YYWW)	Compliant Schneider Electric declaration of conformity
REACH	Reference not containing SVHC above the threshold Reference not containing SVHC above the threshold
Product environmental profile	Available Product Environmental Profile
Product end of life instructions	Need no specific recycling operations

Contractual warranty

Warranty period	18 months
-----------------	-----------

08234 is replaced by:

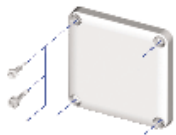

Composition accessories NSYAEDSB520TB

Double bar screws, Ø5 mm, for THALASSA boxes with 20 mm cover height.

Qty 1

Reason for Substitution: Rebranding | Substitution date: 31 October 2009 | -