


Product data sheet

Specifications

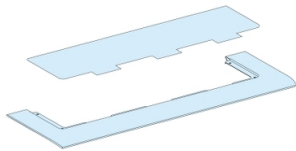

CUT-OUT METAL PLATE + PLASTIC INTERFACE W600 PRISMA G IP30

08880

⚠ Discontinued on: Apr 25, 2023

⚠ Discontinued

Main

Range	Prisma
Range Of Product	Prisma G
Product Or Component Type	Roof plate
Range Compatibility	Prisma Prisma G enclosure
Product Compatibility	IP31 enclosure IP30 enclosure IP43 enclosure
Device Application	Low voltage electrical distribution
Enclosure Type	Metal enclosure Indoor enclosure
Installation Description	Wall-mounted enclosure - width 600 mm Floor-standing enclosure - width 600 mm
Provided Equipment	Top 1 gland plate Top 1 plate with cut-outs
Standards	IEC 61439-1 for enclosure IEC 61439-2 for enclosure

Complementary

Material	Treated sheet steel Plastic
Protective Treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Surface Finish	Matt Smooth
Colour	White (RAL 9001)
Width	600 mm
Height	35 mm
Depth	195 mm
Net Weight	0.96 kg
Quantity Per Set	Set of 1

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	5 cm

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Package 1 Width	20 cm
Package 1 Length	68 cm
Package 1 Weight	972 g
Unit Type Of Package 2	P12
Number Of Units In Package 2	30
Package 2 Height	42 cm
Package 2 Width	80 cm
Package 2 Length	120 cm
Package 2 Weight	41 kg

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓ Reach Free Of Svhc

✓ Toxic Heavy Metal Free

✓ Mercury Free

✓ Rohs Exemption Information Yes

Certifications & Standards

Eu Rohs Directive Pro-active compliance (Product out of EU RoHS legal scope)
[EU RoHS Declaration](#)

China Rohs Regulation [China RoHS declaration](#)
Pro-active China RoHS declaration (out of China RoHS legal scope)

Environmental Disclosure [Product Environmental Profile](#)