


Product data sheet

Specifications

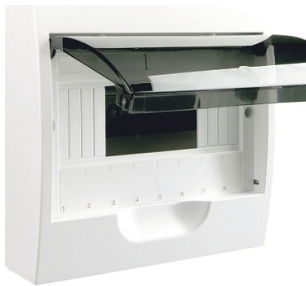

Mini Pragma surface enclosure - IP 40 - 1 x 12 modules - opaque door

13344

 **Discontinued on:** Mar 31, 2022

 **Discontinued**

Main

Range	Mini Pragma
Product Or Component Type	Enclosure
Enclosure Type	Modular enclosure
Nb Of 18 Mm Modules Per Row	12
Nb Of Horizontal Rows	1
Provided Equipment	1 marking kit 1 insulating plug
Type Of Door	Opaque

Complementary

Enclosure Mounting	Surface
9 Mm Pitches	24
Total Number Of 18 Mm Modules	12
[In] Rated Current	63 A
Type Of Rail	DIN
Locking Options Description	Keylock option
Enclosure Material	Enclosure: self-extinguishing material
Colour	Enclosure: white (RAL 9003)

Environment

Standards	EN 60439-3 IEC 60695-2-1 EN 50102 IEC 23-3 IEC 60529 IEC 60439-3
Fire Resistance	Back part: 650 °C (30 s) conforming to IEC 60695-2-1 Front face: 650 °C (30 s) conforming to IEC 60695-2-1
Ik Degree Of Protection	IK07 conforming to EN 50102

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	9.5 cm

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Package 1 Width	25.5 cm
Package 1 Length	20 cm
Package 1 Weight	0.545 kg

Contractual warranty

Warranty	18 months
----------	-----------