


30510 has not been replaced. Please contact your customer care center for more information.

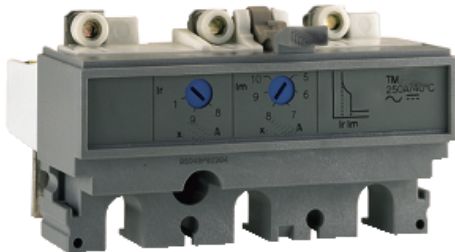

ⓘ Discontinued

Main

Range of product	NS100...250
Product or component type	Trip unit
Range compatibility	Compact NS160 Compact NS250
Device application	Motor
Poles description	4P
Protected poles description	3t
Neutral position	Left
Network type	AC
Network frequency	50/60 Hz
Trip unit name	MA
Trip unit technology	Magnetic
Trip unit protection functions	I
Protection type	I : for short-circuit protection (magnetic)
Trip unit rating	150 A at 65 °C

Complementary

Neutral protection setting	No protection
Short-time pick-up adjustment type I _{sd}	Adjustable
[I _{sd}] short-time pick-up adjustment range	9...14 x In

Environment

Standards	IEC 60947-2
Product certifications	LCIE ASTA ASEFA KEMA
IP degree of protection	IP40 conforming to IEC 60529
Pollution degree	3 conforming to IEC 60947
Ambient air temperature for operation	-25...70 °C
Ambient air temperature for storage	-50...85 °C

Contractual warranty

Warranty	18 months
----------	-----------
