


# Product data sheet

Specifications

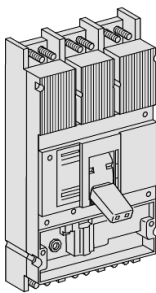

## circuit breaker Compact C1251H - STR35SE - 1250 A - 4 poles 3d and N/2

46798

ⓘ Discontinued

### Main

Range	ComPact
Product Or Component Type	Circuit breaker
Device Short Name	Compact C1251H
Circuit Breaker Name	Compact C1251H
Device Application	Distribution
Poles Description	4P
Protected Poles Description	3t + rN
Network Type	AC
Breaking Capacity Code	H
Trip Unit Name	STR35SE
Trip Unit Technology	Electronic
Trip Unit Rating	1250 A

### Complementary

Network Frequency	50/60 Hz
Control Type	Toggle
Mounting Mode	Fixed
Mounting Support	Backplate Rail
Upside Connection	Front
Downside Connection	Front
[In] Rated Current	1250 A
[Ue] Rated Operational Voltage	690 V
Breaking Capacity	100 kA at 220...240 V 70 kA at 380...415 V 65 kA at 440 V 50 kA at 500 V 40 kA at 690 V
Protection Type	Instantaneous short-circuit protection Short time short-circuit protection Overload protection (long time)
Earth-Leakage Protection	Without

### Environment

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Standards	EN 60947-2
	NEMA AB1
	IEC 60947-2

## Contractual warranty

Warranty	18 months
----------	-----------