



Product data sheet

Specifications

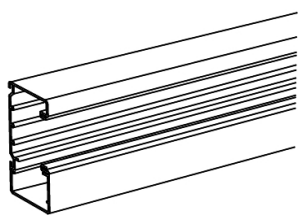

Thorsman - TEK-U161-3 - trunking base - 72 mm - white RAL 9010 - 2.6 m

5532025

 **Discontinued on:** Dec 17, 2020

 **Discontinued**

Main

Range Of Product	Thorsman
Product Name	Thorsman TEK
Product Or Component Type	Installation trunking
Cabling Installation System	Trunking
Colour Tint	White (RAL 9010)
Quantity Per Set	10.4 m

Complementary

Compartment Partitioning	1 compartment
Trunking Dimension	161 x 72 mm
Trunking Material	Plastic
Front Opening Size	80 mm
Fixing Mode	By brackets By screws
Material	PVC (polyvinyl chloride)
Length	2600 mm
Height	161 mm
Width	72 mm

Environment

Quality Labels	CE
Standards	EN 50085-1:1997/A1 EN 50085-1:1998 KEMA 55A:1984 SS 424 10 02:1993
Ambient Air Temperature For Operation	-20...60 °C
Ip Degree Of Protection	IP20

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	7.5 cm
Package 1 Width	16.5 cm

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Package 1 Length	600 cm
Package 1 Weight	13.68 kg