


# Product data sheet

## Characteristics

# 716070

## Wibe - 90° interior bend 15-400 - steel hot-dip galvanized

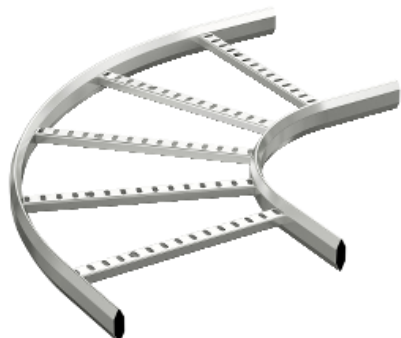

### Main

Range	Wibe
Range of product	Wibe Cable Ladders
Device short name	15
Product or component type	90° interior bend

### Complementary

Direction change type	Horizontal
Inner radius	268 mm
Type of side profile	Closed profile
Type of rung	Perforated profile
Product destination	400 mm width cable ladder
Material with surface treatment	Steel, hot-dip galvanized
Corrosion class	C3/C4
Height	55 mm
Width	797 mm
Depth	797 mm
Product weight	340 kg / set of 100

### Environment

Mounting location	For area with high level of environmental corrosion, humidity and airborne pollution, such as industrial and coastal areas, chemical plants
-------------------	---

### Contractual warranty

Warranty period	18 months
-----------------	-----------