


# Product data sheet

## Characteristics

# 727347

## Wibe - 90° interior bend 15-200 - stainless steel AISI 316L

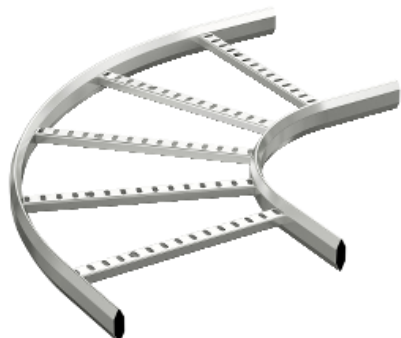

### Main

Range	Wibe
Range of product	Wibe Cable Ladders
Device short name	15
Product or component type	90° interior bend

### Complementary

Direction change type	Horizontal
Inner radius	268 mm
Type of side profile	Closed profile
Type of rung	Perforated profile
Product destination	200 mm width cable ladder
Material with surface treatment	Stainless steel AISI 316L
Corrosion class	C5-M
Height	55 mm
Width	597 mm
Depth	597 mm
Product weight	240 kg / set of 100

### Environment

Mounting location	For area with almost permanent high levels of humidity, airborne pollution and salt, such as purify-ing plants and offshore
-------------------	-----------------------------------------------------------------------------------------------------------------------------

### Contractual warranty

Warranty period	18 months
-----------------	-----------