


Product data sheet

Characteristics

727349

Wibe - 90° interior bend 15-400 - stainless steel AISI 316L

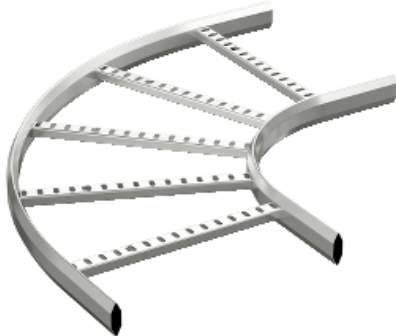

Main

Range	Wibe
Range of product	Wibe Cable Ladders
Device short name	15
Product or component type	90° interior bend

Complementary

Direction change type	Horizontal
Inner radius	268 mm
Type of side profile	Closed profile
Type of rung	Perforated profile
Product destination	400 mm width cable ladder
Material with surface treatment	Stainless steel AISI 316L
Corrosion class	C5-M
Height	55 mm
Width	797 mm
Depth	797 mm
Product weight	340 kg / set of 100

Environment

Mounting location	For area with almost permanent high levels of humidity, airborne pollution and salt, such as purify-ing plants and offshore
-------------------	---

Contractual warranty

Warranty period	18 months
-----------------	-----------

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications