


Product data sheet

Specifications

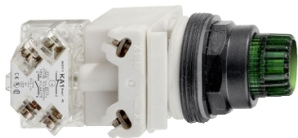

green illuminated pushbutton Ø 30 -
projecting spring return - 48 V - 1 C/
O

9001SK2L36LGG

⚠ Discontinued on: Jan 8, 2021

⚠ Discontinued

Main

Range Of Product	Harmony 9001SK
Product Or Component Type	Illuminated push-button
Device Short Name	9001SK
Type Of Operator	spring return
Operator Profile	Green projecting, unmarked
Light Block Supply	Direct 48 V AC/DC

Complementary

Bezel Material	Plastic
Mounting Diameter	30 mm
Shape Of Signaling Unit Head	Octagonal
Light Source	Green LED
Bulb Base	BA 9s
[Us] Rated Supply Voltage	48 V AC/DC
Contacts Type And Composition	Without contact block
Connections - Terminals	Screw clamp terminals 1 x 0.22...2 x 1.5 mm² conforming to EN/IEC 60947-1
Tightening Torque	0.8 N.m conforming to EN/IEC 60947-1
Shape Of Screw Head	Cross slotted
Mechanical Durability	5000000 cycles
Operating Position	Any position
[Ui] Rated Insulation Voltage	250 V (pollution degree 3) conforming to EN/IEC 60947-1
[Uimp] Rated Impulse Withstand Voltage	2.5 kV conforming to EN/IEC 60947-1
Contact Operation	Standard
Short-Circuit Protection	10 A cartridge fuse conforming to EN/IEC 60947-5-1
[Ith] Conventional Free Air Thermal Current	10 A
Net Weight	0.181 kg
Device Presentation	Basic element

Environment

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Standards	JIS C 4520 EN/IEC 60947-1 UL 508 JIS C 852 EN/IEC 60947-5-1 EN/IEC 60947-5-4 CSA C22.2 No 14
Product Certifications	UL 508 NEMA
Protective Treatment	TC
Ambient Air Temperature For Storage	-40...70 °C
Ambient Air Temperature For Operation	-25...70 °C
Vibration Resistance	7 gn (f= 2...500 Hz) conforming to IEC 60068-2-6
Shock Resistance	50 gn conforming to IEC 60068-2-27
Electrical Shock Protection Class	Class II conforming to IEC 61140
Ip Degree Of Protection	IP66 conforming to IEC 60529
Nema Degree Of Protection	NEMA 1 NEMA 12 NEMA 13 NEMA 2 NEMA 3 NEMA 3R NEMA 4 NEMA 4X

Packing Units


Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	4.572 cm
Package 1 Width	5.334 cm
Package 1 Length	9.144 cm
Package 1 Weight	181.437 g

Contractual warranty

Warranty	18 months
----------	-----------

Dimensions Drawings

Dimensions

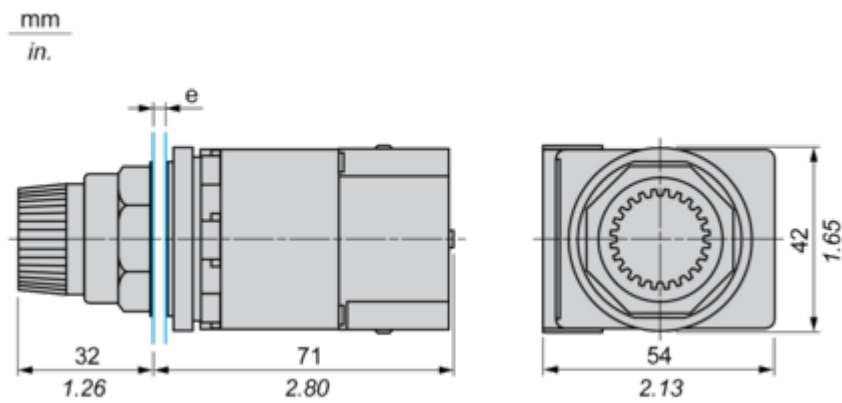


e panel thickness: 1 to 6 mm/ 0.04 to 0.24 in.

Mounting and Clearance

Contact Block Mounting Position

Top and Rear views

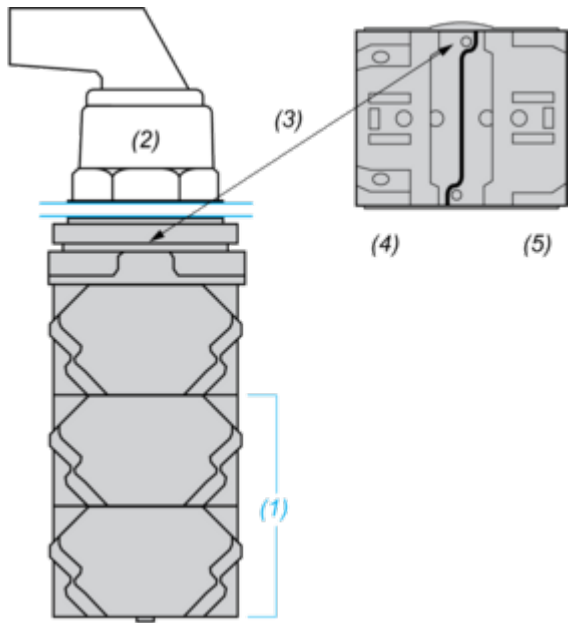

- (1) It is possible to mount up to 3 levels of contacts blocks (maximum of 6 contacts blocks)
- (2) Operator
- (3) Locating notch
- (4) Side 1
- (5) Side 2