


# Product data sheet

Specifications

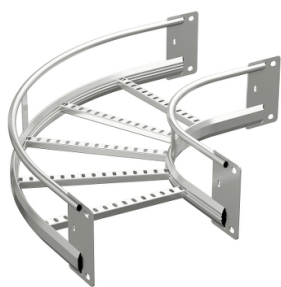

## Wibe - 90° interior bend 20C-400 - steel hot-dip galvanized

CSU795147

 **Discontinued on:** Jan 3, 2022

 **Discontinued**

**Important message:** This product belongs to Cable Support which is no longer commercialized by Schneider Electric. As per the first of January 2022 the commercialization is managed by Wibe-Group, Please follow the link [www.wibe-group.com](http://www.wibe-group.com) for further details.

### Main

Range Of Product	Wibe Cable Ladders
Device Short Name	20C
Product Or Component Type	90° interior bend

### Complementary

Direction Change Type	Horizontal
Inner Radius	268 mm
Type Of Rung	Perforated profile
Product Destination	Reinforced cable ladder 397 mm width
Material With Surface Treatment	Steel, hot-dip galvanized
Corrosion Class	C3/C4
Height	190 mm
Width	825 mm
Depth	825 mm
Net Weight	700 kg / set of 100

### Environment

Mounting Location	Area with high level of environmental corrosion, humidity and airborne pollution industrial and coastal areas, chemical plants
Standards	NEMA 20C

### Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	19 cm
Package 1 Width	82.5 cm
Package 1 Length	82.5 cm
Package 1 Weight	6.193 kg

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications