


# Product data sheet

Specifications

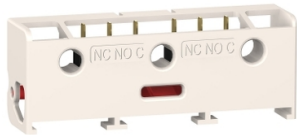

Auxiliary contact block, TeSys DF, 2NC, 5A, disconnecter, signalling contact, instantaneous

DF14AM2

## Main

Range	TeSys
Device Short Name	DF14
Product Or Component Type	Auxiliary contact block
Auxiliary Contacts Operation	Instantaneous
Pole Contact Composition	2 NC
Connections - Terminals	Faston connector

## Complementary

Range Compatibility	TeSys TeSys DF
[Ui] Rated Insulation Voltage	250 VAC
[Ue] Rated Operational Voltage	24...240 V AC AC-15 24...240 V DC DC-13
[Ith] Conventional Free Air Thermal Current	5 A
Minimum Switching Current	30 mA
Minimum Switching Voltage	10 V
Net Weight	0.029 kg

## Environment

Ambient Air Temperature For Operation	-20...60 °C
Ambient Air Temperature For Storage	-40...80 °C

## Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	2.0 cm
Package 1 Width	3.0 cm
Package 1 Length	7.9 cm
Package 1 Weight	17.0 g
Unit Type Of Package 2	S03
Number Of Units In Package 2	120
Package 2 Height	30.0 cm
Package 2 Width	30.0 cm

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Package 2 Length	40.0 cm
Package 2 Weight	2.753 kg

## Contractual warranty

Warranty	18 months
----------	-----------

## Sustainability





**Green Premium™ label** is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)

## Well-being performance

 Reach Free Of Svhc	
 Toxic Heavy Metal Free	
 Mercury Free	
 Rohs Exemption Information	<a href="#">Yes</a>
<b>Reach Regulation</b>	<a href="#">REACH Declaration</a>
<b>Eu Rohs Directive</b>	Compliant <a href="#">EU RoHS Declaration</a>
<b>China Rohs Regulation</b>	<a href="#">China RoHS declaration</a> Pro-active China RoHS declaration (out of China RoHS legal scope)
<b>Weee</b>	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins
<b>California Proposition 65</b>	WARNING: Cancer - <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>