



Product data sheet

Specifications

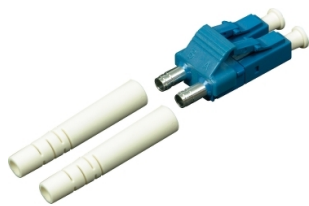

LC Connector, Single-Mode, 2.0mm

DFXOLCXSPR20

 **Discontinued on:** Aug 4, 2021

 **Discontinued**

Main

Range Of Product	Digilink
Product Or Component Type	Single-mode connector

Complementary

Connector Type	LC
Maximum Insertion Loss	0.3 dB
Minimum Number Of Matings	500 cycles
Cable Outer Diameter	2 mm
Product Compatibility	For 9/125 µm optical fibre

Environment

Ambient Air Temperature For Operation	-20...80 °C
Product Certifications	UL listed
Standards	ISO/IEC 11081 EIA/TIA-568-B

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	2 cm
Package 1 Width	6.5 cm
Package 1 Length	7.5 cm
Package 1 Weight	5.407 g

Contractual warranty

Warranty	18 months
----------	-----------

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Sustainability

Green Premium™ label is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)



Transparency

Eu Rohs Directive	Not applicable, out of EU RoHS legal scope
Environmental Disclosure	Product Environmental Profile
Circularity Profile	No need of specific recycling operations