


DXYCAT3UT25P has not been replaced. Please contact your customer care center for more information.

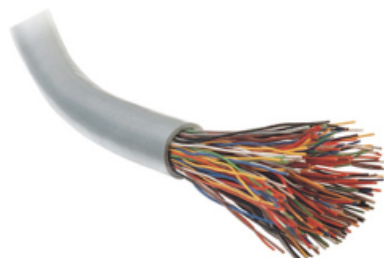

ⓘ Discontinued

Main

Product or component type	Copper cable
Cable shielding type	UTP
Communication network category	3
Colour tint	Grey

Complementary

Type of cable	25 pairs cable
Nominal velocity propagation	69 %
Capacitance unbalance	3.28 pF/m
Cable outer diameter	11 mm
Cable length	305 m
AWG gauge	AWG 24
Thickness	Insulation : 0.2 mm Jacket : 1.1 mm
Pulling force	40 N
Material	For jacket : PVC (polyvinyl chloride)

Environment

Standards	ISO/IEC 11801 ANSI/TIA-568-A
-----------	---------------------------------

Offer Sustainability

RoHS (date code: YYWW)	Compliant - since 1622 - Schneider Electric declaration of conformity Schneider Electric declaration of conformity
Product end of life instructions	Need no specific recycling operations

Contractual warranty

Warranty period	18 months
-----------------	-----------