


Product data sheet

Specifications

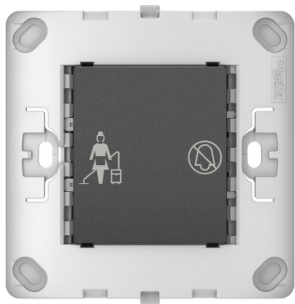

Illuminated "Do Not Disturb" & "Please Clean Up" Symbols, Black

E8432DM_GA_DG

⚠ Discontinued on: Oct 29, 2018

⚠ End-of-service on: Nov 19, 2018

⚠ Discontinued

Main

Range	ZENcelo
Product Or Component Type	Message indicator
Local Signalling	Please clean up: indicator light, neon (green) Do not disturb: indicator light, neon (orange)
Colour Tint	Black

Complementary

Device Mounting	Flush Surface
Clamping Connection Capacity	3 x 2.5 mm ² for solid cable(s) 3 x 2.5 mm ² for stranded cable(s) 4 x 1.5 mm ² for solid cable(s) 4 x 1.5 mm ² for stranded cable(s)
[Ue] Rated Operational Voltage	250 V AC 50/60 Hz
Material	Brass: contact Polycarbonate: base Polycarbonate: cover Polycarbonate: grid plate Polycarbonate: surround
Connections - Terminals	Illuminated indicators: folded terminal
Embedding Depth	19.57 mm
Width	87 mm
Height	87 mm
Depth	27.72 mm

Environment

Ambient Air Temperature For Operation	-5...35 °C
Relative Humidity	0...95 %
Environmental Characteristic	No UV resistant
Operating Altitude	<= 2000 m
Standards	EN 60669-1 IEC 60669-1 GB 16915.1 MS IEC 60669-1

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications