


Product data sheet

Specifications

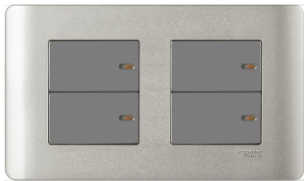

16AX/20A 2+2 Gang 1 Way Full-Flat Switch with Ondicator, Sliver Satin

E84T34-1_SA

Main

Range	ZENcelo
Product Or Component Type	Switch
Load Type	Fluorescent lamp Resistive Inductive Incandescent lamp
Colour Tint	Silver satin

Complementary

Device Mounting	Flush Surface
Switch Function	1-way
Rated Current	16 AX at 250 V AC 50/60 Hz 20 A at 250 V AC 50/60 Hz
Local Signalling	Mechanical indicator (amber)
Number Of Gangs	2 gangs
Material	Polycarbonate: cover Polycarbonate: dolly Polycarbonate: grid plate Polycarbonate: surround
Connections - Terminals	Brass rod terminals
Embedding Depth	22.75 mm
Width	147 mm
Height	87 mm
Depth	31 mm

Environment

Ambient Air Temperature For Operation	-5...35 °C
Relative Humidity	0...95 %
Environmental Characteristic	No UV resistant
Operating Altitude	2000 m
Standards	IEC 60669-1 EN 60669-1

Contractual warranty

Warranty	18 months
----------	-----------

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

