


# Product data sheet

Specifications

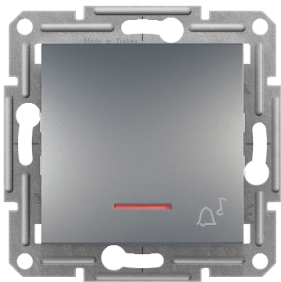

1pole pushbutton with locator light "bell", screwless terminals, wo frame, steel

EPH1700162

⚠ Discontinued on: Jun 30, 2023

⚠ Discontinued

## Main

|                           |                             |
|---------------------------|-----------------------------|
| Range                     | Asfora                      |
| Product Or Component Type | Push-button                 |
| Device Presentation       | Mechanism with fixing frame |
| Number Of Rocker          | 1                           |
| Colour Tint               | Steel                       |
| Type Of Packing           | Flow-pack                   |

## Complementary

|                         |                                       |
|-------------------------|---------------------------------------|
| Device Mounting         | Flush                                 |
| Local Signalling        | LED                                   |
| Power Range             | 2300 W                                |
| Rated Current           | 10 A at 250 V AC                      |
| Number Of Cables        | 2 cable(s) 2.5 mm²                    |
| Cable Stiffness         | Flexible<br>Rigid<br>Solid stranded   |
| Wire Stripping Length   | 13.0 mm                               |
| Material                | ABS (acrylonitrile butadiene-styrene) |
| Surface Finish          | Painted                               |
| Conductor Material      | Copper                                |
| Fixing Mode             | Screws or claws51...70 mm             |
| Connections - Terminals | Screwless terminals                   |
| Marking                 | Bell symbol                           |
| Width                   | 71 mm                                 |
| Height                  | 71 mm                                 |
| Depth                   | 43.0 mm                               |
| Projecting Depth        | 15 mm                                 |
| Net Weight              | 0.0608 kg                             |

## Environment

|           |             |
|-----------|-------------|
| Standards | IEC 60669-1 |
|-----------|-------------|

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

|                                       |                  |
|---------------------------------------|------------------|
| Product Certifications                | TSE<br>VDE<br>NF |
| Quality Labels                        | CE<br>UKR        |
| Ip Degree Of Protection               | IP20             |
| Ambient Air Temperature For Operation | -5...40 °C       |

## Packing Units

|                              |         |
|------------------------------|---------|
| Unit Type Of Package 1       | PCE     |
| Number Of Units In Package 1 | 1       |
| Package 1 Height             | 7.1 cm  |
| Package 1 Width              | 7.1 cm  |
| Package 1 Length             | 4.3 cm  |
| Package 1 Weight             | 67.0 g  |
| Unit Type Of Package 2       | CAR     |
| Number Of Units In Package 2 | 10      |
| Package 2 Height             | 9.1 cm  |
| Package 2 Width              | 18.5 cm |
| Package 2 Length             | 27.5 cm |
| Package 2 Weight             | 738.0 g |
| Unit Type Of Package 3       | S04     |
| Number Of Units In Package 3 | 120     |
| Package 3 Height             | 30.0 cm |
| Package 3 Width              | 40.0 cm |
| Package 3 Length             | 60.0 cm |
| Package 3 Weight             | 9.52 kg |

# Sustainability

**Green Premium™ label** is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency   RoHS/REACH

## Well-being performance

Rohs Exemption Information   [Yes](#)

## Certifications & Standards

|                          |   |
|--------------------------|---|
| Reach Regulation         | <a href="#">REACH Declaration</a>   |
| Eu Rohs Directive        | Compliant<br><a href="#">EU RoHS Declaration</a>  |
| China Rohs Regulation    | <a href="#">China RoHS declaration</a><br>Pro-active China RoHS declaration (out of China RoHS legal scope)                 |
| Environmental Disclosure | <a href="#">Product Environmental Profile</a>   |
| Weee                     | The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins |
| Circularity Profile      | No need of specific recycling operations  |