


Product data sheet

Specifications

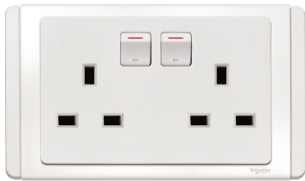

13A Twin 3 Pin Switched Socket Outlet with White LED, White

ET3025D_EWWW

⚠ Discontinued on: Jun 30, 2023

⚠ Discontinued

Main

Range	Neo C-Metro
Product Or Component Type	Power socket-outlet
Switch Function	2-pole
Outlet Poles Configuration	3P with shutters
Outlet Standard	SS 145 MS 589 BS 1363
Bulb Type	LED, white
Colour Tint	White

Complementary

Wiring Device Mounting	Flush Surface
Rated Current	13 A at 250 V AC 50/60 Hz
Material	Brass: contact Copper with silver onlay: bridge Nylon: shutter Polycarbonate: grid plate Polycarbonate: surround Steel with brass plating: screws Steel with brass plating: terminals
Load Type	Resistive
Connections - Terminals	Pillar terminals
Width	147 mm
Height	87 mm
Depth	18 mm

Environment

Ambient Air Temperature For Operation	0...40 °C
Relative Humidity	0...95 %
Environmental Characteristic	Indoor use
Standards	BS 1363 SS 145 MS 589

Packing Units

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	9 cm
Package 1 Width	14.8 cm
Package 1 Length	18 cm
Package 1 Weight	1 kg

Contractual warranty

Warranty	18 months
----------	-----------

Sustainability

Green Premium™ label is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)



RoHS/REACH

Well-being performance

✓ Toxic Heavy Metal Free

✓ Mercury Free

✓ Rohs Exemption Information [Yes](#)

Certifications & Standards

Reach Regulation	REACH Declaration
Eu Rohs Directive	Compliant EU RoHS Declaration
China Rohs Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Circularity Profile	End of Life Information