


# Product data sheet

## Characteristics

# ETK41925

Ultra - minitrunking - 40 x 25 mm - self-adhesive - PVC - white - 2 m

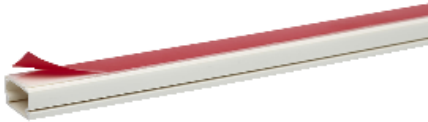

### Main

Product or component type	Mini trunking
Colour tint	White RAL 9010
Quantity per set	60 m

### Complementary

Trunking material	Plastic
Compartment partitioning	1 compartment
Trunking dimension	40 x 25 mm
Fixing mode	Power cable : screw-fixed Low voltage cable : adhesive tape Pre-punched fixing hole with distance of 230 mm between centers
Material	PVC (polyvinyl chloride)
Length	2000 mm
Height	40 mm
Width	25 mm

### Environment

IP degree of protection	IP40
IK degree of protection	IK07
Ambient air temperature for operation	-5...60 °C
Environmental health and issues	Cadmium free Lead free
Product certifications	Low voltage directive 2006/95/EC
Standards	EN 50085-1 : 2005 EN 50085-2-1 : 2006

### Offer Sustainability

RoHS (date code: YYWW)	Compliant - since 0844 - Schneider Electric declaration of conformity <a href="#">Schneider Electric declaration of conformity</a>
Product environmental profile	Available <a href="#">Product Environmental Profile</a>
Product end of life instructions	Need no specific recycling operations

Contractual warranty

---

Warranty period	18 months
-----------------	-----------

---