


Product data sheet

Characteristics

G35TSBPXFM10K30F

MGE Galaxy 3500 Input Transformer MCCB 208/208 10-30kVA Floormount

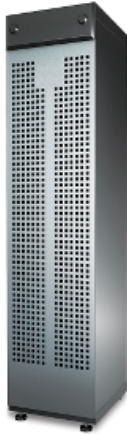

Purchase

APC
 [G35TSBPXFM10K30F](#)

Overview

Description	Bypass cabinet with 208/208 integrated input transformer
Model Name	MGE Galaxy 3500 Input Transformer MCCB 208/208 10-30kVA Floormount
Includes	Installation guide
Standard Lead Time	Usually Ships within 2 Weeks
Product Distribution	Anguilla , Antigua And Barbuda , Argentina , Aruba , Bahamas , Barbados , Belize , Bermuda , Bolivia , Brazil , Canada , Cayman Islands , Chile , Colombia , Costa Rica , Cuba , Dominica , Dominican Republic , Ecuador , El Salvador , Falkland Islands (Malvinas) , Grenada , Guatemala , Guyana , Haiti , Honduras , Jamaica , Mexico , Netherlands Antilles , Nicaragua , Panama , Paraguay , Peru , Puerto Rico , SAINT KITTS AND NEVIS , SAINT LUCIA , SAINT VINCENT AND THE GRENADINES , Trinidad And Tobago , Turks And Caicos Islands , United States , Uruguay , Venezuela , VIRGIN ISLANDS (UNITED STATES)

Output

Nominal Output Voltage	208V 3PH
------------------------	----------

Input

Nominal Input Voltage	208V 3PH
Input Frequency	60 Hz

Physical

Net Weight	330.91 kg
Maximum Height	1487 mm
Maximum Width	351 mm
Maximum Depth	837 mm
Shipping Weight	365 kg
Shipping Height	1664 mm
Shipping Width	724 mm
Shipping Depth	1105 mm

Environmental

Operating Environment	0 - 40 °C
Operating Relative Humidity	0 - 95 %
Operating Elevation	0-3000 meters
Storage Temperature	0 - 45 °C
Storage Relative Humidity	0 - 95 %
Storage Elevation	0-9000 meters

Conformance

Approvals	CSA , CSA C22.2 No. 107.1 , UL 1778
Standard warranty	1 year repair or replace