


G35TXR6B6

MGE Galaxy 3500 Extended Run Enclosure with 6 Battery Modules

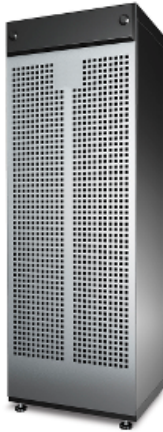

Purchase

APC
 G35TXR6B6

Overview

Model Name	MGE Galaxy 3500 Extended Run Enclosure with 6 Battery Modules
Includes	Installation guide , User Manual
Standard Lead Time	Usually Ships within 2 Weeks
Product Distribution	Andorra , United Arab Emirates , Afghanistan , Antigua And Barbuda , Anguilla , Albania , Armenia , Netherlands Antilles , Angola , Argentina , Austria , Australia , Aruba , Azerbaijan , Bosnia And Herzegovina , Barbados , Bangladesh , Belgium , Burkina Faso , Bulgaria , Bahrain , Burundi , Benin , Bermuda , Brunei Darussalam , Bolivia , Brazil , Bahamas , Bhutan , Botswana , Belarus , Belize , Canada , CONGO, THE DEMOCRATIC REPUBLIC OF THE , Central African Republic , Congo , Switzerland , Cote D'Ivoire , Cook Islands , Chile , Cameroon , Colombia , Costa Rica , Serbia And Montenegro , Cuba , Cyprus , Czech Republic , Germany , Djibouti , Denmark , Dominica , Dominican Republic , Algeria , Ecuador , Estonia , Egypt , Western Sahara , Spain , Ethiopia , Finland , Fiji , Falkland Islands (Malvinas) , France , Gabon , United Kingdom , Grenada , Georgia , Ghana , Gibraltar , Gambia , Guinea , Equatorial Guinea , Greece , Guatemala , Guyana , Honduras , Croatia , Haiti , Hungary , Indonesia , Ireland , Israel , India , Iraq , Iran (Islamic Republic Of) , Iceland , Italy , Jamaica , Jordan , Kenya , Cambodia , SAINT KITTS AND NEVIS , KOREA, REPUBLIC OF , Kuwait , Cayman Islands , Kazakhstan , Lebanon , SAINT LUCIA , Liechtenstein , Sri Lanka , Liberia , Lesotho , Lithuania , Luxembourg , Latvia , Morocco , Moldova , Republic Of , Madagascar , Macedonia , Mali , Myanmar , Mauritania , Malta , Mauritius , Malawi , Mexico , Malaysia , Mozambique , Namibia , Niger , Nigeria , Nicaragua , Netherlands , Norway , Nepal , New Zealand , Oman , Panama , Peru , Papua New Guinea , Philippines , Pakistan , Poland , Puerto Rico , Portugal , Paraguay , Reunion , Romania , Russian Federation , Rwanda , Saudi Arabia , Sudan , Sweden , Singapore , Slovenia , Slovakia (Slovak Republic) , Sierra Leone , Senegal , Somalia , El Salvador , Turks And Caicos Islands , Chad , Togo , Thailand , Turkmenistan , Tunisia , East Timor , Turkey , Trinidad And Tobago , TANZANIA , UNITED REPUBLIC OF , Ukraine , Uganda , United States , Uruguay , Uzbekistan , SAINT VINCENT AND THE GRENADINES , Venezuela , VIRGIN ISLANDS (UNITED STATES) , Viet Nam , Yemen , Mayotte , South Africa , Zambia , Zimbabwe

Input

Nominal Input Voltage	208V 3PH , 400V 3PH
Input Frequency	50/60 Hz

Batteries & Runtime

Battery Volt-Amp-Hour Capacity	16590
Battery Type	Maintenance-free sealed Lead-Acid battery with suspended electrolyte : leakproof
Battery mounting	Enclosed battery cabinet
Battery mounting	3 - 5
Included Battery Modules	6
Battery Placement	External Frame

Physical

Net Weight	776 kg
Maximum Height	1499 mm
Maximum Width	523 mm
Maximum Depth	925 mm
Shipping Weight	807 kg
Shipping Width	650 mm
Shipping Height	1643 mm
Shipping Depth	1062 mm

Environmental

Operating Environment	0 - 40 °C
Storage Temperature	0 - 30 °C

Conformance

Standard warranty	1 year repair or replace
-------------------	--------------------------