


# Product data sheet

Specifications

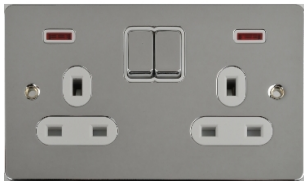

Switched socket, Ultimate Flat plate, complete product, 1P, screw terminal, IP20, chrome

GU3221WPC

 **Discontinued on:** Sep 30, 2022

 **Discontinued**

## Main

Aesthetic Name	Flat plate
Product Or Component Type	Switched socket
Rated Current	13 A at 230 V AC 50 Hz
Fixing Mode	By screws M3.5 x 30 mm
Colour Tint	Chrome

## Complementary

Device Presentation	Complete product
Outlet Poles Configuration	1P
Outlet Standard Description	3 pins
Outlet Standard	British
Actuator	Rocker
Number Of Gangs	2 gangs
Earth Circuit	Standard earth
Pilot Light	Neon indicator
Device Mounting	Wall mounted
Connections - Terminals	Screw terminal
Material	Steel
Quantity Per Set	Set of 1
Height	88 mm
Width	148 mm
Depth	30 mm

## Environment

Ip Degree Of Protection	IP20
Standards	BS 1363

## Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	4 cm

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Package 1 Width	9.6 cm
Package 1 Length	15.5 cm
Package 1 Weight	279.5 g
Unit Type Of Package 2	CAR
Number Of Units In Package 2	50
Package 2 Height	18 cm
Package 2 Width	42.5 cm
Package 2 Length	50 cm
Package 2 Weight	14.527 kg
Unit Type Of Package 3	PAM
Number Of Units In Package 3	1000
Package 3 Height	106.5 cm
Package 3 Width	100 cm
Package 3 Length	120 cm
Package 3 Weight	310.536 kg

## Contractual warranty

Warranty	18 months
----------	-----------