


# Product data sheet

Specifications

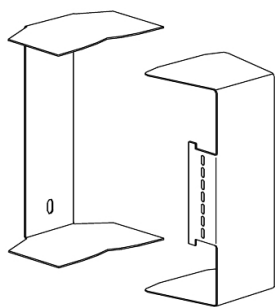

## Stago - internal corner adjustable - 170 x 65 mm - steel - white - RAL1013

INS5553302

! Discontinued

! Discontinued on: Sep 26, 2017

! End-of-service on: Oct 26, 2017

### Main

Range Of Product	Stago
Product Or Component Type	Internal corner
Colour Tint	White (RAL 1013)
Quantity Per Set	Set of 1

### Complementary

Trunking Dimension	170 x 65 mm
Compartment Partitioning	1 compartment
Front Opening Size	80 mm
Nominal Cross Section	11050 mm²
Fixing Mode	By screws
Material	Zinc coated sheet steel
Surface Finish	Powder coated
Length	115 mm
Height	170 mm
Width	65 mm
Compatibility Code	WGX-IA170

### Environment

Standards	EN 50085-1:2005 EN 50085-2-1:2006
Directives	73/23/EEC - low voltage directive
Ambient Air Temperature For Operation	-20...80 °C
Ip Degree Of Protection	IP20

### Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	17 cm
Package 1 Width	6.5 cm
Package 1 Length	11.5 cm

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

---

Package 1 Weight	342 g
------------------	-------

## Contractual warranty

---

Warranty	18 months
----------	-----------