


Product data sheet

Specifications

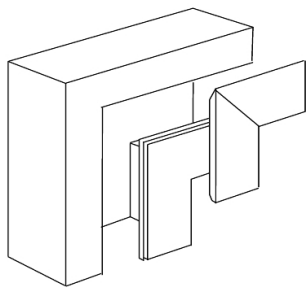

Stago - bend 90 kit, riser/dropper - 170 x 65 mm - steel - optional colour

INS5553501

⚠ Discontinued on: Sep 12, 2018

⚠ End-of-service on: Dec 7, 2018

⚠ Discontinued

Main

Range Of Product	Stago
Product Or Component Type	Bend
Provided Equipment	1 x cover
Colour Tint	Optional
Quantity Per Set	Set of 1

Complementary

Trunking Dimension	170 x 65 mm
Compartment Partitioning	1 compartment
Operating Angle	90 °
Direction Change Type	Vertical
Front Opening Size	80 mm
Nominal Cross Section	11050 mm²
Fixing Mode	By brackets By screws
Material	Zinc coated sheet steel
Surface Finish	Powder coated
Length	250 mm
Height	170 mm
Width	65 mm

Environment

Standards	EN 50085-1:2005 EN 50085-2-1:2006
Directives	73/23/EEC - low voltage directive
Ambient Air Temperature For Operation	-20...60 °C
Ip Degree Of Protection	IP20

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	17 cm

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Package 1 Width	6.5 cm
Package 1 Length	25 cm
Package 1 Weight	1338 g