


Product data sheet

Specifications

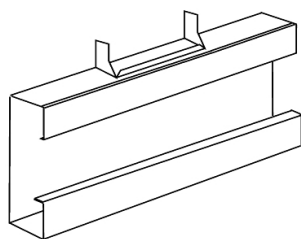

Stago - branching piece - 170 x 65 mm - steel - white - RAL 1013

INS5553702

Main

Range Of Product	Stago
Product Or Component Type	Branching piece
Colour Tint	White (RAL 1013)
Quantity Per Set	Set of 1

Complementary

Trunking Dimension	170 x 65 mm
Compartment Partitioning	1 compartment
Nominal Cross Section	11050 mm²
Front Opening Size	80 mm
Fixing Mode	By screws By brackets
Material	Zinc coated sheet steel
Length	300 mm
Height	170 mm
Width	65 mm

Environment

Standards	EN 50085-1:2005 EN 50085-2-1:2006
Directives	73/23/EEC - low voltage directive
Ambient Air Temperature For Operation	-20...60 °C
Ip Degree Of Protection	IP20

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications