


Product data sheet

Specifications

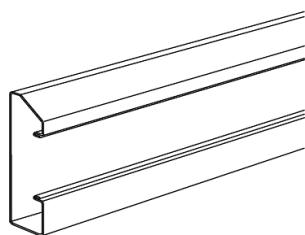

Stago - trunking base - 165V x 52 mm - 2.5 m - steel - optional colour

INS5554001

 **Discontinued on:** Jun 11, 2019

 **Discontinued**

Main

Range Of Product	Stago
Product Or Component Type	Installation trunking
Cabling Installation System	Trunking
Colour Tint	Optional
Quantity Per Set	2.5 m

Complementary

Trunking Dimension	165V x 52 mm
Trunking Material	Steel
Nominal Cross Section	8580 mm²
Compartment Partitioning	1 compartment
Front Opening Size	80 mm
Fixing Mode	By brackets Screw-fixed
Material	Zinc coated sheet steel
Surface Finish	Powder coated
Length	2500 mm
Height	165 mm
Width	52 mm

Environment

Standards	93/68/EEC EN 50085-1: 2005 EN 50085-2-1 : 2006 73/23/EEC
Ambient Air Temperature For Operation	-20...60 °C
Ip Degree Of Protection	IP20

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	16.5 cm
Package 1 Width	5.2 cm

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Package 1 Length	250 cm
Package 1 Weight	2985 g