


# Product data sheet

## Characteristics

# INS5554411

Stago - external corner - 165W x 52 mm - steel - optional colour

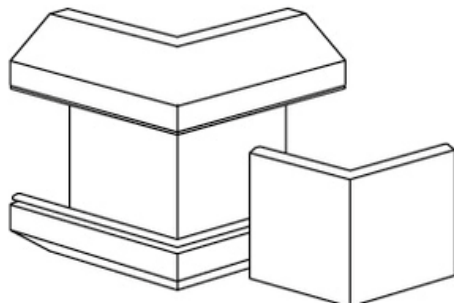

⚠ Discontinued

INS5554411 has not been replaced. Please contact your customer care center for more information.

### Main

|                           |                 |
|---------------------------|-----------------|
| Range of product          | Stago           |
| Product or component type | External corner |
| Colour tint               | Optional        |
| Quantity per set          | Set of 1        |

### Complementary

|                          |                          |
|--------------------------|--------------------------|
| Trunking dimension       | 165W x 52 mm             |
| Compartment partitioning | 1 compartment            |
| Front opening size       | 80 mm                    |
| Nominal cross section    | 8580 mm <sup>2</sup>     |
| Fixing mode              | By brackets<br>By screws |
| Material                 | Zinc coated sheet steel  |
| Surface finish           | Powder coated            |
| Length                   | 252 mm                   |
| Height                   | 165 mm                   |
| Width                    | 52 mm                    |

### Environment

|                                       |                                      |
|---------------------------------------|--------------------------------------|
| Standards                             | EN 50085-1:2005<br>EN 50085-2-1:2006 |
| Directives                            | 73/23/EEC - low voltage directive    |
| Ambient air temperature for operation | -20...60 °C                          |
| Environmental health and issues       | Halogen free                         |
| IP degree of protection               | IP20                                 |

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications