


Product data sheet

Specifications

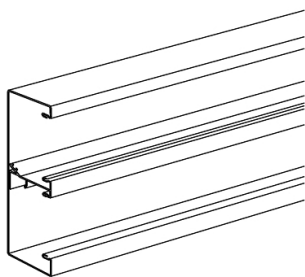

Stago - trunking base - 233-2 x 72 mm - 2.5 m - steel - white - RAL 1013

INS5558002

⚠ Discontinued on: Nov 30, 2017

⚠ End-of-service on: Dec 15, 2017

⚠ Discontinued

Main

Range Of Product	Stago
Product Or Component Type	Installation trunking
Cabling Installation System	Trunking
Colour Tint	White (RAL 1013)
Quantity Per Set	2.5 m

Complementary

Trunking Dimension	233 x 72 mm
Trunking Material	Steel
Nominal Cross Section	16776 mm²
Compartment Partitioning	2 compartments
Front Opening Size	80 mm
Fixing Mode	By brackets Screw-fixed
Material	Zinc coated sheet steel
Surface Finish	Powder coated
Length	2500 mm
Height	233 mm
Width	72 mm

Environment

Standards	73/23/EEC EN 50085-1: 2005 EN 50085-2-1 : 2006 93/68/EEC
Ambient Air Temperature For Operation	-20...60 °C
Ip Degree Of Protection	IP20

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	23.3 cm

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Package 1 Width	7.2 cm
Package 1 Length	250 cm
Package 1 Weight	3695 g