


# Product data sheet

Specifications

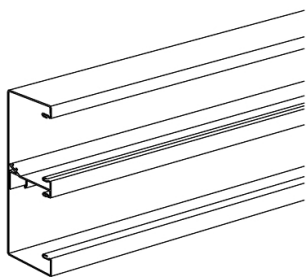

## Stago - trunking base - 233-2 x 72 mm - 2.5 m - steel - white - RAL 9010

INS5558003

 **Discontinued on:** Jan 3, 2022

 **Discontinued**

**Important message:** This product belongs to Cable Support which is no longer commercialized by Schneider Electric. As per the first of January 2022 the commercialization is managed by Wibe-Group, Please follow the link [www.wibe-group.com](http://www.wibe-group.com) for further details.

### Main

Range Of Product	Stago
Product Or Component Type	Installation trunking
Cabling Installation System	Trunking
Colour Tint	White (RAL 9010)
Quantity Per Set	2.5 m

### Complementary

Trunking Dimension	233 x 72 mm
Trunking Material	Steel
Nominal Cross Section	16776 mm²
Compartment Partitioning	2 compartments
Front Opening Size	80 mm
Fixing Mode	By brackets Screw-fixed
Material	Zinc coated sheet steel
Surface Finish	Powder coated
Length	2500 mm
Height	233 mm
Width	72 mm

### Environment

Standards	93/68/EEC EN 50085-2-1 : 2006 73/23/EEC EN 50085-1: 2005
Ambient Air Temperature For Operation	-20...60 °C
Ip Degree Of Protection	IP20

### Packing Units

Unit Type Of Package 1	PCE
------------------------	-----

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Number Of Units In Package 1	1
Package 1 Height	23.3 cm
Package 1 Width	7.2 cm
Package 1 Length	250 cm
Package 1 Weight	3.695 kg

## Sustainability

**Green Premium™ label** is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency   RoHS/REACH

## Well-being performance

✓ Reach Free Of Svhc

✓ Toxic Heavy Metal Free

✓ Mercury Free

✓ Rohs Exemption Information   Yes

## Certifications & Standards

Reach Regulation	<a href="#">REACH Declaration</a>
Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
China Rohs Regulation	<a href="#">China RoHS declaration</a> Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
Circularity Profile	No need of specific recycling operations