


Product data sheet

Specifications

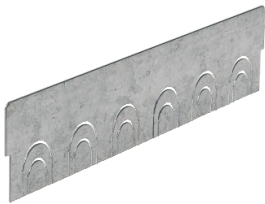

OptiLine 45 - adaptor

ISM50393

⚠ Discontinued on: Jun 30, 2023

⚠ Discontinued

Main

Range	OptiLine
Cabling Installation System	Floor box
Product Type	Adaptor
Type Of Floor	Screeded floor
Floor Box Shape	Rectangular
Quantity Package 1 / Unit	5 pieces

Complementary

Suitable For	For 1-6 conduits for steel floor box
Number Of Modules	Without modules
Product Material	Sheet steel galvanized
Length	403 mm
Height	83 mm
Width	1.5 mm

Environment

Operating Temperature	-25...60 °C
Ip Degree Of Protection	IP20

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	8.3 cm
Package 1 Width	40.3 cm
Package 1 Length	0.1 cm
Package 1 Weight	292 g
Unit Type Of Package 2	BB1
Number Of Units In Package 2	5
Package 2 Height	2 cm
Package 2 Width	40.5 cm
Package 2 Length	7.2 cm

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Package 2 Weight	1.5 kg
Unit Type Of Package 3	BAG
Number Of Units In Package 3	30
Package 3 Height	30 cm
Package 3 Width	29.9 cm
Package 3 Length	39.8 cm
Package 3 Weight	9.361 kg

Contractual warranty

Warranty	18 months
----------	-----------