


Product data sheet

Specifications

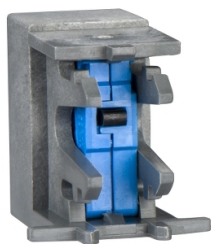

Blown fuse indicator 3P (only for NFC type)- 1NO+1NC- for Fupact INF50 to 63

LV480446

⚠ Discontinued on: Dec 1, 2021

⚠ Discontinued

Main

Range Of Product	INF40 INF63
Range	FuPact
Device Short Name	blown fuse indicator
Product Or Component Type	Blown Fuse Indicator
Device Application	Display
Range Compatibility	FuPact Fupact INF fuse-switch disconnecter
Poles Description	3P
Signal Contacts Composition	1 NO + 1 NC

Complementary

[Ith] Conventional Free Air Thermal Current	16 A
[Ie] Rated Operational Current	AC-15: 6 A at 24 V AC 50/60 Hz DC-12: 2 A at 48 V DC DC-12: 6 A at 24 V DC AC-15: 2 A at 660/690 V AC 50/60 Hz AC-15: 3 A at 440 V AC 50/60 Hz AC-15: 4 A at 380/415 V AC 50/60 Hz AC-15: 6 A at 110 V AC 50/60 Hz AC-15: 6 A at 220/240 V AC 50/60 Hz AC-15: 6 A at 250 V AC 50/60 Hz AC-15: 6 A at 48 V AC 50/60 Hz DC-12: 0.1 A at 380/415 V DC DC-12: 0.1 A at 440 V DC DC-12: 0.4 A at 220/240 V DC DC-12: 0.4 A at 250 V DC DC-12: 1.1 A at 110 V DC
Minimum Load	10 mA at 24 V

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	1 cm
Package 1 Width	10 cm
Package 1 Length	17 cm
Package 1 Weight	29 g

Contractual warranty

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Warranty

18 months

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓ Reach Free Of Svhc

✓ Toxic Heavy Metal Free

✓ Mercury Free

✓ Rohs Exemption Information [Yes](#)

✓ Pvc Free

Certifications & Standards

Eu Rohs Directive [Compliant](#)
[EU RoHS Declaration](#)

China Rohs Regulation [China RoHS declaration](#)
Pro-active China RoHS declaration (out of China RoHS legal scope)

Environmental Disclosure [Product Environmental Profile](#)