



Product data sheet

Specifications

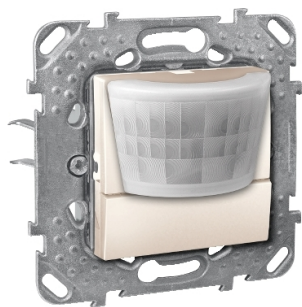

Unica KNX - movement detector - 230 VAC - 2 m - ivory

MGU50.533.25

 **Discontinued on:** Dec 31, 2017

 **Discontinued**

Main

Range	Unica
Aesthetic Name	Unica KNX
Product Or Component Type	Movement detector
Device Presentation	Mechanism with zamak fixing frame + long claws
Cover Plate Colour Tint	Ivory

Complementary

[Ue] Rated Operational Voltage	230 V AC +/- 10 % at 50/60 Hz
Movement Detection Area	9 x 9 m(PIR mounting height 2.15m)
Detection Angle	Full 180°
Number Of Modules	2 modules
Light Intensity Adjustment	10...1000 lux rotary switch 10...2000 lux ETS
Time Delay Range	1 s...8 min (rotary switch) 1 s...255 h (ETS)
Clamping Connection Capacity	<= 2 x 2.5 mm² for flexible cable(s) <= 2 x 2.5 mm² for rigid cable(s)
Connections - Terminals	Screwless terminals
Material	ASA + PC: mechanism cover Zamak: fixing frame
Fixing Mode	Long claws
Mounting Height	1...2.5 m
Depth	56 mm
Embedding Depth	34 mm

Environment

Ip Degree Of Protection	IP20
Ambient Air Temperature For Operation	-5...45 °C
Environmental Characteristic	Acetone Window-cleaning fluid Alcohol Liquid soap Petrol Oil UV resistant Bleach

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Standards	LV directive
	EMC directive

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	8 cm
Package 1 Width	9.5 cm
Package 1 Length	9.5 cm
Package 1 Weight	0.159 kg

Contractual warranty

Warranty	18 months
----------	-----------