


# Product data sheet

Specifications

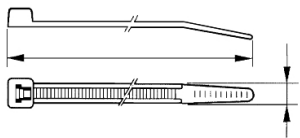

Adjustable cable tie 295x3.6 black .  
Polyamide 6/6. Composition: 1000  
units.

NSYLN35290

⚠ Discontinued

## Main

Accessory / Separate Part Category	Cable management accessory
Product Or Component Type	Cable tie
Application	Multi-purpose
Device Composition	1 cable tie
Quantity Per Set	Set of 1000

## Complementary

Mounting Support	Cable ties fixing supports
Material	Black polyamide 6/6
Length	295 mm
Width	3.6 mm

## Environment

Fire Resistance	650 °C conforming to UL 94 V2
Environmental Characteristic	Not sensitive to engine oil, greases, oil products, etc Good resistance to bases and organic acids, chlorinated solvent Not resistant to phenol
Maximum Tightening Diameter	76 mm
Minimum Pulling Resistance	13.6 Ohm

## Contractual warranty

Warranty	18 months
----------	-----------

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications