


Product data sheet

Specifications

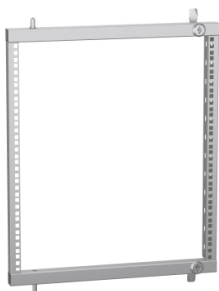

Spacial SF/SM partial 19" swing rack - 601 mm

NSYRSWP12

Main

Range	Spacial
Accessory / Separate Part Category	Mounting accessory
Product Or Component Type	19" rack
Application	Electronic application
For Enclosure Nominal Dimensions	- H: 601 mm
Rack Type	Partial swing
Mounting Location	Front of enclosure
Mounting Support	Partial 19" swing rack support
Range Compatibility	Spacial Spacial SF Spacial Spacial SM
Device Composition	1 rack
Number Of Units 19"	12

Complementary

Material	Steel
Enclosure/Cubicle Description	Floor-standing enclosure
Surface Finish	Zinc coated
Lock Type	Lock 5 mm double bar
Fixing Mode	By fixing element
Adjustment	Adjustable in depth every 25 mm
Permanent Permissible Load	2 kg per unit
Opening Of The 19" Racks	Reversible 120 °
Height	601 mm
Width	600 mm
Depth	601 mm

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	7.5 cm
Package 1 Width	51.5 cm
Package 1 Length	61.5 cm

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Package 1 Weight	3.44 kg
Unit Type Of Package 2	PAM
Number Of Units In Package 2	20
Package 2 Height	105.0 cm
Package 2 Width	100.0 cm
Package 2 Length	120.0 cm
Package 2 Weight	82.0 kg

Contractual warranty

Warranty	18 months
----------	-----------

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency RoHS/REACH

Well-being performance



Mercury Free



RoHS Exemption Information

Yes

Certifications & Standards

Reach Regulation

[REACH Declaration](#)

Eu RoHS Directive

Pro-active compliance (Product out of EU RoHS legal scope)

China RoHS Regulation

[China RoHS declaration](#)

Product out of China RoHS scope. Substance declaration for your information

Environmental Disclosure

[Product Environmental Profile](#)

Circularity Profile

No need of specific recycling operations