


# Product data sheet

Specifications

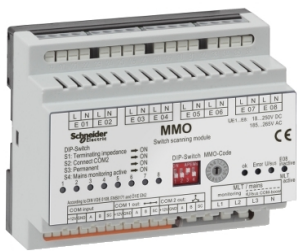

## Exiway - MMO - light switch query module

OVA18506

### Main

Range	Exiway
Product Name	Exiway Power Control
Device Short Name	MMO
Product Or Component Type	Light switch query module
Device Application	Control

### Complementary

Range Compatibility	Exiway Exiway Power Control Exiway Power Control Pico central battery system Exiway Exiway Power Control Exiway Power Control Nano central battery system Exiway Exiway Power Control Exiway Power Control Mega central battery system Exiway Exiway Power Control Exiway Power Control Multi central battery system
[Ue] Rated Operational Voltage	24 V
Rated Power In Va	0.5 VA
Number Of Inputs	8 galvanic isolation
Input Voltage	18...255 V DC 185...255 V AC 50 Hz
Communication Port Support	RS485
Depth	90 mm
Width	105 mm
Height	64.5 mm
Net Weight	0.24 kg

### Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	10.5 cm
Package 1 Width	6.45 cm
Package 1 Length	9.0 cm
Package 1 Weight	250.0 g

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

## Sustainability

**Green Premium™ label** is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)

## Well-being performance

 Toxic Heavy Metal Free

 Mercury Free

 Rohs Exemption Information [Yes](#)

<b>Eu Rohs Directive</b>	Compliant
	<a href="#">EU RoHS Declaration</a>

<b>China Rohs Regulation</b>	<a href="#">China RoHS declaration</a>
	Pro-active China RoHS declaration (out of China RoHS legal scope)