


Product data sheet

Specifications

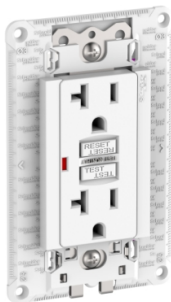

Orion - duplex American socket outlet 2P+E 20A 120/125/127V~ GFCI with fixing-frame white

S703310045

 **Discontinued on:** Jun 30, 2023

 **Discontinued**

Main

Range Of Product	Orion
Range	Orion
Product Or Component Type	Socket-outlet
Device Presentation	Mechanism with fixing frame
Outlet Poles Configuration	2P + E with shutter
Fixing Mode	By screws
Type Of Packing	Flow-pack
Sale Per Indivisible Quantity	1
Rated Current	20 A at 125 V AC 60 Hz 15 A at 120/127 V AC

Complementary

Device Mounting	Flush
Outlet Standard	American
Outlet Standard Description	GFCI
Ground Lug Position	Straight 0° position
Number Of Modules	3 modules 120 x 82.5 mm
Local Signalling	LED (red/orange) for trip/end of life
Surface Finish	Glossy
Surface Treatment	Untreated
Ambient Air Temperature For Storage	-20...60 °C
Protection Type	Earth-leakage protection
Dielectric Strength	2000 V
Ambient Air Temperature For Operation	-5...35 °C
Electrical Durability	5000 cycles
Connections - Terminals	3 screw-clamp terminals
Clamping Connection Capacity	1.5...4 mm² for rigid cable(s) 1.5...4 mm² for stranded cable(s) 1.5...4 mm² for flexible cable(s)
Wire Stripping Length	18 mm

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Material	PC (polycarbonate) FR: casing PC (polycarbonate) FR: centre plate ABS (acrylonitrile butadiene-styrene): adaptor frame
Height	113 mm
Width	71 mm
Depth	40 mm
Embedding Depth	30.6 mm
Standards	UL 94 UL 943 UL 498 NMX J-508 ANCE

Environment

Product Certifications	NOM RETIE
Ik Degree Of Protection	IK04
Ip Degree Of Protection	IP20
Environmental Characteristic	Oil Liquid soap Alcohol Hydrogen peroxide (H2O2) Petrol Window-cleaning fluid Bleach UV resistant Acetone

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	4.0 cm
Package 1 Width	7.5 cm
Package 1 Length	20.0 cm
Package 1 Weight	136.0 g

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)

Eu Rohs Directive

Under investigation
