



Product data sheet

Specifications

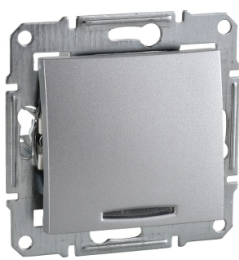

Sedna - 1pole 2way switch - 10AX indicator light, aluminium

SDN0401160

 **Discontinued on:** Aug 31, 2018

 **Discontinued**

Main

Range	Sedna
Product Or Component Type	Switch
Device Presentation	Mechanism with fixing frame
Device Application	Control
Switch Function	1-pole 2-way
Colour Tint	Aluminium

Complementary

Device Mounting	Flush
Surface Finish	Glossy
Kind Of Terminals	Screwless terminals
Accessory / Separate Part Type	Claw and screw for mechanism
Power Range	2300 W
Wire Structure	Flexible Rigid
Wire Stripping Length	13 mm
Fixing Mode	Claws, span of claws working range: 51...70 mm Screws
Height	71 mm
Width	71 mm
Depth	37 mm
Depth Of Visual Part	12 mm
Net Weight	0.059995 kg
Market Segment	Residential Small commercial

Environment

Ip Degree Of Protection	IP20
Conformity Mark	CE
Product Certifications	GOST-R
Standards	IEC 60669-1

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	7.1 cm
Package 1 Width	7.1 cm
Package 1 Length	4.2 cm
Package 1 Weight	77.13 g

Contractual warranty

Warranty	18 months
----------	-----------