


Product data sheet

Specifications

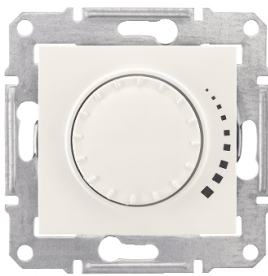

Dimmer, Sedna, two way, rotary, 500VA, cream

SDN2200523

⚠ Discontinued on: Dec 30, 2023

⚠ Discontinued

Main

Range Of Product	Sedna
Product Or Component Type	Dimmer
Device Presentation	Mechanism with fixing frame
Device Application	Light control
Colour Tint	Cream
Kind Of Terminals	Pillar terminals

Complementary

Device Mounting	Flush
Dimmer Control	Rotary push type
Switch Function	2-way
Load Type	230 V AC halogen lamp: 60...500 W Low voltage halogen lamp with ferromagnetic transformer: 60...500 VA 230 V AC incandescent lamp: 60...500 W
Rated Voltage	230 V AC
Protection Type	Fuse protection
Fuse Type	F2.5AH 250 V
Main Colour Tint	Cream
Material	Thermoplastic ABS-UV stabilised
Surface Finish	Glossy
Terminal Capacity	1 cable(s) 2.5 mm ²
Wire Structure	Flexible Rigid
Wire Stripping Length	7 mm
Fixing Mode	Claws, span of claws working range: 51...80 mm Screws
Height	71 mm
Width	71 mm
Depth	47.5 mm
Depth Of Visual Part	20 mm
Net Weight	0.13541 kg
Market Segment	Small commercial Residential

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Environment

Standards	EN 60669-2-1
Conformity Mark	CE
Product Certifications	GOST-R
Ip Degree Of Protection	IP20

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	6.000 cm
Package 1 Width	8.500 cm
Package 1 Length	8.500 cm
Package 1 Weight	156.000 g
Unit Type Of Package 2	BB1
Number Of Units In Package 2	8
Package 2 Height	9.500 cm
Package 2 Width	18.500 cm
Package 2 Length	27.500 cm
Package 2 Weight	1.339 kg
Unit Type Of Package 3	S04
Number Of Units In Package 3	96
Package 3 Height	30.000 cm
Package 3 Width	40.000 cm
Package 3 Length	60.000 cm
Package 3 Weight	16.710 kg

Contractual warranty

Warranty	18 months
----------	-----------

Sustainability

Green Premium™ label is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)

Well-being performance

 Mercury Free	
 Rohs Exemption Information	Yes
Reach Regulation	REACH Declaration
Eu Rohs Directive	Compliant with Exemptions
China Rohs Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information
Weee	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins