


# Product data sheet

Specifications



## ConneXium Standard Unmanaged Switch - 8 ports for copper

TCSESSU083FN0

 **Discontinued on:** Sep 30, 2021

 **Discontinued**

### Main

Range Of Product	ConneXium
Product Or Component Type	Ethernet TCP/IP unmanaged switch
Concept	Transparent Ready
Communication Port Protocol	Ethernet TCP/IP
Port Ethernet	10/100BASE-TX - 8 port(s) copper cable
Maximum Number Of Switches In Cascade	Unlimited

### Complementary

Integrated Connection Type	Shielded RJ45 copper cable
Transmission Support Medium	Twisted shielded pairs cable CAT 5E for copper cable
Maximum Cable Distance Between Devices	100 m copper cable
[Us] Rated Supply Voltage	12...24 V
Supply Voltage Limits	9.6...32 V DC SELV
Power Consumption In W	1.5 W
Electrical Connection	Removable connector 3 ways power supply
Mounting Support	35 mm symmetrical DIN rail
Marking	CE UL RCM
Local Signalling	1 LED (green) for power supply 1 LED per channel (yellow) for data rate (ETH LINK) 1 dual colour LED (green/yellow) for link status
Ethernet Cabling System	TF switches
Width	38 mm
Height	102 mm
Depth	79 mm
Net Weight	0.150 kg

### Environment

Ambient Air Temperature For Operation	0...60 °C
Relative Humidity	10...95 % non-condensing
Ip Degree Of Protection	IP30

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Directives	2014/35/EU - low voltage directive 2014/30/EU - electromagnetic compatibility
Standards	UL 61010 EN/IEC 61131
Product Certifications	CE UL RCM

## Packing Units


Unit Type Of Package 1	PCE
Number Of Units In Package 1	1

## Contractual warranty

Warranty	18 months
----------	-----------

Dimensions Drawings

Dimensions

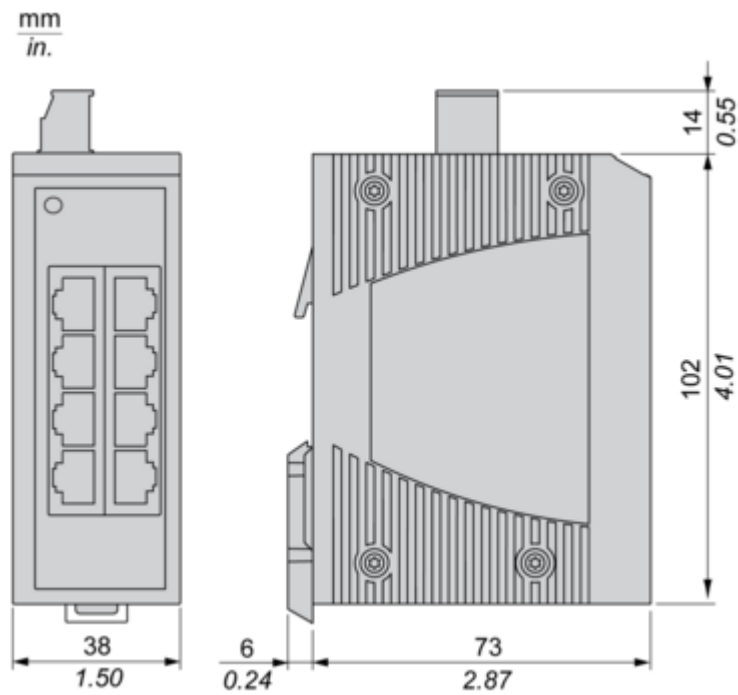

Connections and Schema

Power Wiring

---

