

Product data sheet

Specifications



Prewired rotating mirror beacon,
Harmony XVR, 106 mm, green,
without buzzer, 24 V AC DC

XVR10B03

⚠ Discontinued on: Mar 31, 2023

⚠ End-of-service on: Apr 15, 2023

⚠ Discontinued

Main

| | |
|---------------------------|---|
| Range Of Product | Harmony XVR |
| Product Or Component Type | Prewired rotating mirror beacon |
| Sound Signalling | Without |
| Device Short Name | XVR |
| Mounting Diameter | 106 mm |
| Ip Degree Of Protection | IP55 (with accessory) conforming to IEC 60529 IP23 conforming to IEC 60529 |
| [Us] Rated Supply Voltage | 24 V AC/DC |
| Light Source | High luminosity LED, green |

Complementary

| | |
|--|---|
| Material | ABS (acrylonitrile butadiene-styrene): body part PMMA (polymethyl methacrylate): globe |
| Cad Overall Width | 106 mm |
| Cad Overall Depth | 106 mm |
| Net Weight | 0.5 kg |
| Marking | CE |
| Product Mounting | By 3 M4 screws |
| Supply Voltage Limits | 19...30 V DC 21.6...26.4 V AC |
| [Uimp] Rated Impulse Withstand Voltage | 0.8 kV |
| Current Consumption | 125 mA |
| Flashing Frequency | 2.3 Hz |
| Clamping Connection Capacity | 0.83 mm² |
| Awg Gauge | AWG 18 |
| Cable Length | 400 mm |

Environment

| | |
|------------------------|------------------------------|
| Standards | EN 61000-6-2 EN 61000-6-4 |
| Product Certifications | UL |
| Protective Treatment | TC |

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

| | |
|---------------------------------------|----------------------------------|
| Ambient Air Temperature For Storage | -35...70 °C |
| Ambient Air Temperature For Operation | -10...50 °C |
| Electrical Shock Protection Class | Class II conforming to IEC 61140 |

Packing Units

| | |
|------------------------------|----------|
| Unit Type Of Package 1 | PCE |
| Number Of Units In Package 1 | 1 |
| Package 1 Height | 19.5 cm |
| Package 1 Width | 13.8 cm |
| Package 1 Length | 14.0 cm |
| Package 1 Weight | 619.0 g |
| Unit Type Of Package 2 | S04 |
| Number Of Units In Package 2 | 8 |
| Package 2 Height | 30.0 cm |
| Package 2 Width | 40.0 cm |
| Package 2 Length | 60.0 cm |
| Package 2 Weight | 6.204 kg |

Contractual warranty

| | |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

Sustainability

Green Premium™ label is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)



Transparency RoHS/REACH

Well-being performance

Rohs Exemption Information [Yes](#)


Certifications & Standards

| | |
|---------------------------|---|
| Reach Regulation | REACH Declaration |
| Eu Rohs Directive | Pro-active compliance (Product out of EU RoHS legal scope) |
| China Rohs Regulation | China RoHS declaration |
| Environmental Disclosure | Product Environmental Profile |
| Circularity Profile | End of Life Information |
| California Proposition 65 | WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov |

Dimensions Drawings

Rotating Mirror Beacon

Dimensions

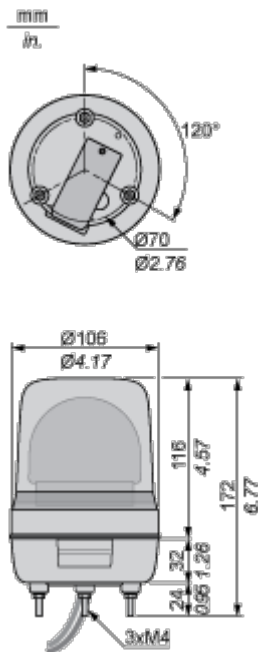

Mounting and Clearance

Rotating Mirror Beacon

Panel Cut-out

