


Product data sheet

Specifications

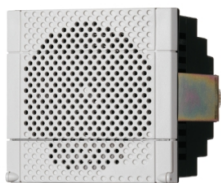

Electronic alarm, Harmony XVS,
white, PNP, 72mm DIN rail,
0...90dB, 16 tones alarm, 4
channels, 12...24V DC

XVS72BMWP

Main

| | |
|---------------------------|------------------|
| Range Of Product | Harmony XVS |
| Product Or Component Type | Electronic alarm |
| Device Short Name | XVS |

Complementary

| | |
|--|---|
| Colour | White |
| Material | ABS (acrylonitrile butadiene-styrene): body PC (polycarbonate): terminal cover |
| Marking | CE |
| Overvoltage Category | Class II conforming to IEC 61140 |
| Mounting Support | 72 mm DIN rail |
| [Us] Rated Supply Voltage | 12...24 V DC |
| [Uimp] Rated Impulse Withstand Voltage | 0.8 kV |
| Current Consumption | 117 mA at 12 V 125 mA at 24 V 158 mA at 12 V 200 mA at 24 V |
| Clamping Connection Capacity | <= 1 x 1.5 mm² |
| Width | 72 mm |
| Height | 72 mm |
| Depth | 69.3 mm |
| Net Weight | 0.18 kg |

Environment

| | |
|---------------------------------------|---|
| Discrete Output Type | PNP |
| Signalling Type | 16 tones alarm |
| Standards | IEC 61000-6-3 IEC 61000-6-2 UL 464 |
| Product Certifications | UR |
| Protective Treatment | TC |
| Ambient Air Temperature For Storage | -35...70 °C |
| Ambient Air Temperature For Operation | -10...50 °C |
| Ip Degree Of Protection | Panel mounted: IP54 conforming to IEC 60529 |

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

| | |
|-------------|--|
| Noise Level | 0...90 dB (continuous or intermittent tone) at 1 m |
|-------------|--|

Packing Units

| | |
|------------------------------|----------|
| Unit Type Of Package 1 | PCE |
| Number Of Units In Package 1 | 1 |
| Package 1 Height | 10.5 cm |
| Package 1 Width | 9.3 cm |
| Package 1 Length | 9.5 cm |
| Package 1 Weight | 265 g |
| Unit Type Of Package 2 | S03 |
| Number Of Units In Package 2 | 16 |
| Package 2 Height | 30 cm |
| Package 2 Width | 30 cm |
| Package 2 Length | 40 cm |
| Package 2 Weight | 5.164 kg |
| Unit Type Of Package 3 | S03 |
| Number Of Units In Package 3 | 16 |
| Package 3 Height | 30 cm |
| Package 3 Width | 30 cm |
| Package 3 Length | 40 cm |
| Package 3 Weight | 5.164 kg |

Contractual warranty

| | |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓ Mercury Free

✓ Rohs Exemption Information [Yes](#)

Certifications & Standards

| | |
|---------------------------|---|
| Reach Regulation | REACH Declaration |
| Eu Rohs Directive | Pro-active compliance (Product out of EU RoHS legal scope) |
| China Rohs Regulation | China RoHS declaration |
| Environmental Disclosure | Product Environmental Profile |
| Circularity Profile | End of Life Information |
| California Proposition 65 | WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov |

Dimensions Drawings

Electronic Alarm

Dimensions

