

Product data sheet

Specifications



Pre wired connectors XZ, elbowed female, M12, 5 pins, cable PUR 2 m

XZCP1264L2

Main

| | |
|------------------------------------|----------------------------------|
| Range Of Product | Telemecanique Cabling components |
| Accessory / Separate Part Category | Cabling accessory |
| Accessory / Separate Part Type | Pre-wired connectors |
| Series Name | General purpose |

Complementary

| | |
|--------------------------------|---|
| Electrical Connection | Elbowed female connector M12, 5 pins (included earth pin) |
| Cable Connector Fixing | Screw-on |
| Collar Material | Metal |
| Status Led | Without |
| Cable Length | 2 m |
| Cable Outer Diameter | 5.9 mm |
| Cable Composition | 5 x 0.34 mm ² |
| Wire Insulation Material | PUR |
| [Ue] Rated Operational Voltage | 60 V AC 75 V DC |
| [In] Rated Current | 4 A |
| Contact Resistance | 5000 µOhm |
| Minimum Insulating Resistance | 1 GΩ |
| Net Weight | 0.115 kg |

Environment

| | |
|---------------------------------------|--|
| Ip Degree Of Protection | IP69K IP67 IP65 |
| Product Certifications | cULus |
| Ambient Air Temperature For Operation | -40...80 °C static -5...80 °C flexing |
| Ambient Air Temperature For Storage | -40...80 °C |

Packing Units

| | |
|------------------------------|----------|
| Unit Type Of Package 1 | PCE |
| Number Of Units In Package 1 | 1 |
| Package 1 Height | 1.500 cm |

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

| | |
|------------------------------|-----------|
| Package 1 Width | 16.000 cm |
| Package 1 Length | 20.000 cm |
| Package 1 Weight | 85.000 g |
| Unit Type Of Package 2 | S02 |
| Number Of Units In Package 2 | 40 |
| Package 2 Height | 15.000 cm |
| Package 2 Width | 30.000 cm |
| Package 2 Length | 40.000 cm |
| Package 2 Weight | 3.714 kg |

Contractual warranty

| | |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



RoHS/REACH

Well-being performance

✓ Mercury Free

✓ Rohs Exemption Information [Yes](#)


Certifications & Standards

Reach Regulation [REACH Declaration](#)

Eu Rohs Directive Pro-active compliance (Product out of EU RoHS legal scope)

California Proposition 65
WARNING: This product can expose you to chemicals including: Diisononyl phthalate (DINP), which is known to the State of California to cause cancer, and Diisodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov

Dimensions

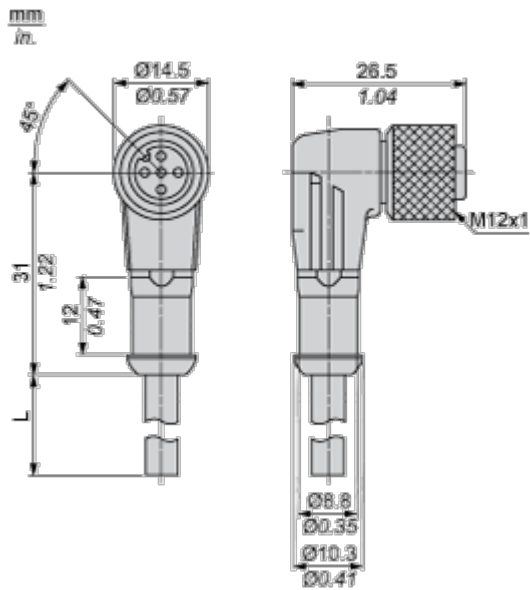


L : Lenght of cable

Connections and Schema

Connections and Schemes

Connectors

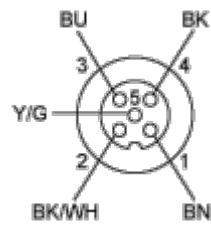

- BU : Blue
- BN : Brown
- BK : Black
- Y/G : Yellow / Green
- BK/WH : Black / White