

Product data sheet

Specifications



Pre wired connectors XZ, elbowed female, M12, 5 pins, cable PUR 5 m

XZCP1264L5

Main

Range Of Product	Telemecanique Cabling components
Accessory / Separate Part Category	Cabling accessory
Accessory / Separate Part Type	Pre-wired connectors
Series Name	General purpose

Complementary

Electrical Connection	Elbowed female connector M12, 5 pins (included earth pin)
Cable Connector Fixing	Screw-on
Collar Material	Metal
Status Led	Without
Cable Length	5 m
Cable Outer Diameter	5.9 mm
Cable Composition	5 x 0.34 mm ²
Wire Insulation Material	PUR
[Ue] Rated Operational Voltage	60 V AC 75 V DC
[In] Rated Current	4 A
Contact Resistance	5000 µOhm
Minimum Insulating Resistance	1 GΩ
Net Weight	0.27 kg

Environment

Ip Degree Of Protection	IP69K IP65 IP67
Product Certifications	cULus
Ambient Air Temperature For Operation	-40...80 °C static -5...80 °C flexing
Ambient Air Temperature For Storage	-40...80 °C

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	3.000 cm

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Package 1 Width	20.000 cm
Package 1 Length	20.000 cm
Package 1 Weight	187.000 g
Unit Type Of Package 2	S02
Number Of Units In Package 2	20
Package 2 Height	15.000 cm
Package 2 Width	30.000 cm
Package 2 Length	40.000 cm
Package 2 Weight	4.100 kg
Unit Type Of Package 3	P06
Number Of Units In Package 3	320
Package 3 Height	75.000 cm
Package 3 Width	60.000 cm
Package 3 Length	80.000 cm
Package 3 Weight	77.220 kg

Contractual warranty

Warranty	18 months
----------	-----------

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



RoHS/REACH

Well-being performance

✓ Mercury Free

✓ Rohs Exemption Information [Yes](#)

Certifications & Standards


Reach Regulation [REACH Declaration](#)

Eu Rohs Directive Pro-active compliance (Product out of EU RoHS legal scope)

California Proposition 65
WARNING: This product can expose you to chemicals including: Diisononyl phthalate (DINP), which is known to the State of California to cause cancer, and Diisodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov

Dimensions Drawings

Dimensions

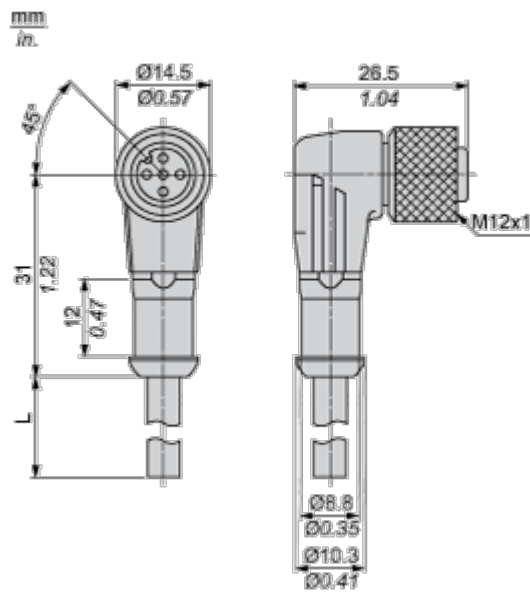


L : Lenght of cable

Connections and Schema

Connections and Schemes

Connectors

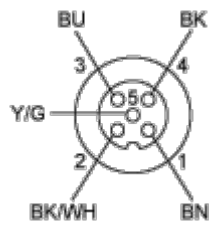

- BU : Blue
- BN : Brown
- BK : Black
- Y/G : Yellow / Green
- BK/WH : Black / White